


Deep groove ball bearings, single row, shield on both sides



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
6	19	6	2,34	0,95	0,04	80000	40000	0,0084	626-2Z *

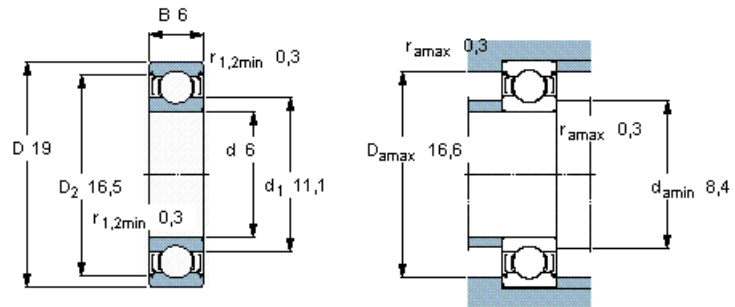

Calculation factors

$k_r = 0,025$
 $f_0 = 13$