



Brand of NTN corporation


Technical data

BB40UU

Standard ball bushings closed



VISUAL (S)

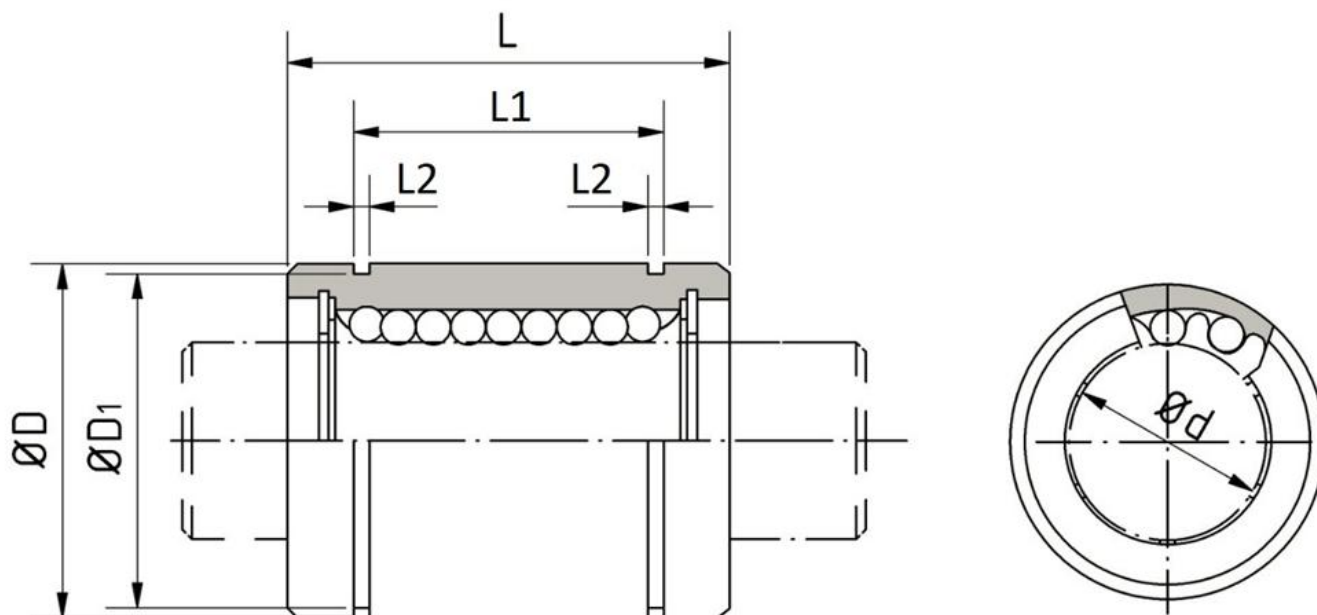

PRODUCT DEFINITION

Brand	SNR
Design type	BBE
Ball bushings category	Standard ball bushings, closed
Standard	JIS dimension
Number of seals	2
Material outer cylinder or steel segments	100Cr6
Material Cage	PA
Initial greasing	Non/No
d - Internal diameter	40 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION	
d - Internal diameter tolerance	0/-0,012
D - External diameter	60 mm
D - External diameter tolerance	0/-0,019
L - Length	80 mm
L - Length tolerance	0/-0,3
L1	60,5 mm
L1 tolerance	0/-0,3
D1 - Diameter	57 mm
L2	2,1 mm
Number of ball rows	6
Mass	0,654 kg

PRODUCT PERFORMANCE	
Cmin	2,357 kN
Cmax	3,017 kN
C0min	4,02 kN
C0max	5,146 kN
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	80 °C

ESHOPDONOTDISPLAY	
Reference	BB40UU
Image	BBE+BB_1.JPG, BBE+BB_3.JPG
Send to Eshop	Yes
Send to Paper Catalog	Yes



BB40UU

Standard ball bushings closed

ESHOPDONOTDISPLAY

Tracepart

Oui/Yes



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15