

## Metal nozzle blow gun

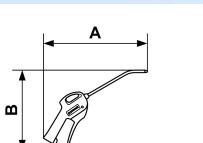
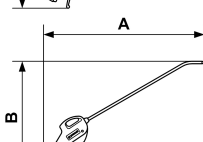

### Technical characteristics

**Max operating pressure:** 10 bar

**Construction:** Polyamide composite body

**Highlight:** Adjust gradually blowing



	A (mm)	B (mm)	BSPP female thread	Air consumption (at 6 bar (Nm <sup>3</sup> /h))	Sound level (at 6 bar (dBA))	Bent tube length (mm)	Parts Numbers
	367	250	G 1/4	15	86	330	<b>27102 MB13</b>
	514	380	G 1/4	14.5	86	500	<b>27102 MB20</b>
	957	650	G 1/4	9.4	81	1000	<b>27102 MB40OSH</b>