




Connectors > PCB Connectors > Wire-to-Board Connectors > Wire-to-Board Connector Assemblies & Housings

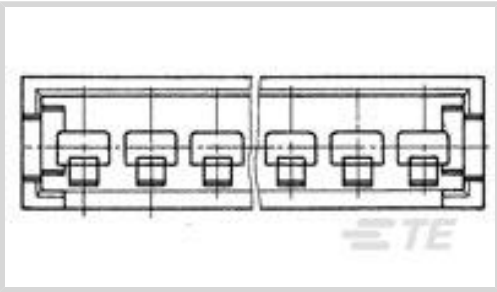

Connector Product Type: **Housing**

Connector & Housing Type: **Plug**

Connector System: **Wire-to-Board**

Number of Positions: **15**

Centerline (Pitch): **2.54 mm [.1 in]**

Features

Product Type Features

Connector Product Type	Housing
Connector & Housing Type	Plug
Connector System	Wire-to-Board
Connector & Contact Terminates To	Wire & Cable

Configuration Features

Number of Positions	15
Number of Rows	1

Body Features

Primary Product Color	Black
-----------------------	-------

Contact Features

Contact Layout	Inline
Contact Type	Pin
Contact Current Rating (Max)	3 A

Termination Features

Termination Method to Wire & Cable	Crimp
------------------------------------	-------

Mechanical Attachment

Panel Mount Feature	Without
Mating Retention Type	Lock



PCB Mount Retention	With
Mating Retention	With
Connector Mounting Type	Cable Mount (Free-Hanging)

Housing Features

Housing Material	LCP (Liquid Crystal Polymer)
Housing Entry Configuration	Both Ends Closed
Centerline (Pitch)	2.54 mm[.1 in]

Dimensions

Connector Height	3.1 mm[.12 in]
Connector Length	7.1 mm
Row-to-Row Spacing	2.54 mm[.1 in]

Usage Conditions

Operating Temperature Range	-40 – 80 °C[-40 – 176 °F]
-----------------------------	---------------------------

Operation/Application

Circuit Application	Signal
---------------------	--------

Industry Standards

UL Flammability Rating	UL 94V-0
Glow Wire Rating	Standard Part - Not Glow Wire

Packaging Features

Packaging Method	Bag
Packaging Quantity	1000

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC



Free

Solder Process Capability

Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts




TE Part # 280363
AMPMODU II REC. HSG, SINGLE ROW, 15 POS.



TE Part # CAT-F439-P65254
2.54mm FFC Connectors Pin Contacts

Also in the Series | AMPMODU IV/V

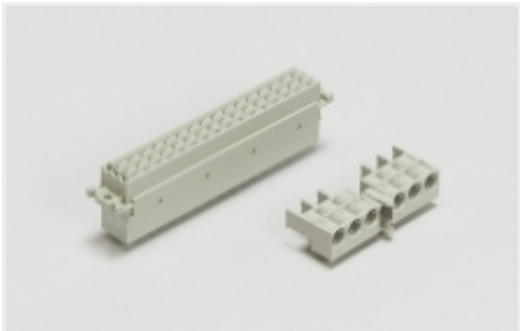


Backplane Connector Housings(1)



Connector Caps & Covers(11)




Connector Contacts(271)

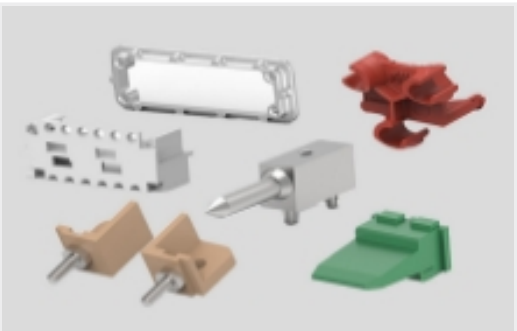

Connector Hardware(10)



Insertion & Extraction Tools(4)

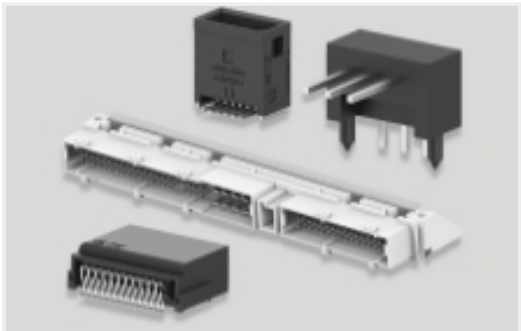

PCB Headers & Receptacles(517)



Power Contacts(207)


Customers Also Bought



TE Part #1658539-1
PIN CONT DUPL PLT STRIP HD-20



TE Part #35345
TERMINAL,PIDG R 12-10 1/4

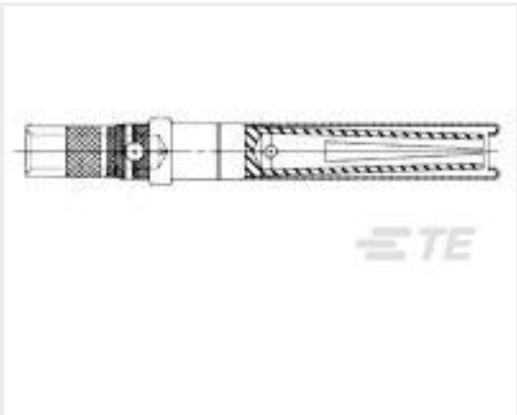

TE Part #205117-1
SKT CONTACT,SZ 16



TE Part #32948
PG R 22-16 COMM 22-18 MIL 8



TE Part #86557-6
FFC PIN ROUND WIRE PLATED



TE Part #1-102241-2
14 MODIV HSG COMP SR .100 POL



TE Part #5225396-7
BNC JACK DUAL CP RG174,188



TE Part #205204-9
CRIMP SNAP PLUG ASSY,SIZE 1



TE Part #201389-1
JACKSCREW-FEMALE -SPEC



TE Part #280363
AMPMODU II REC. HSG, SINGLE ROW, 15 POS.

Documents

Product Drawings

AMPMODU II COSI PIN HSG, SGL ROW, 15 POS

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_280635_J.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_280635_J.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_280635_J.3d_stp.zip

English

3D PDF

English



Customer View Model

[ENG_CVM_280635_H2.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_280635_H2.3d_stp.zip](#)

English

Customer View Model

[ENG_CVM_280635_H2.2d_dxf.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

[Product Specification](#)

English