



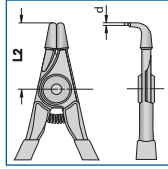

8010 A 01 - A 41

CIRCLIP PLIERS FOR EXTERNAL RETAINING RINGS Form B

- For retaining rings as per DIN 471, DIN 983
- DIN 5254 Form B
- 90° angled tips
- With opening spring
- With clamping protection
- Forged GEDORE chrome-vanadium special hardened and tempered steel
- Precision machined, oil hardened and annealed
- Chrome-plated, with red dipped handles

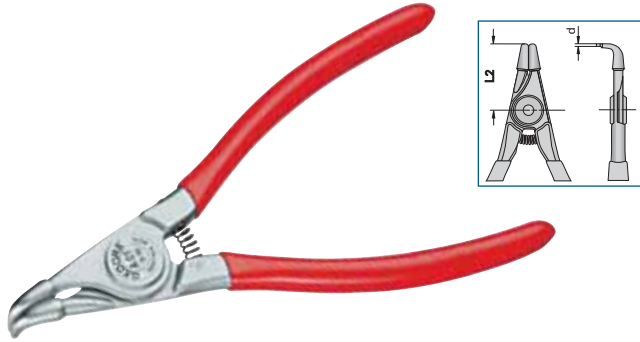


Code	No.	mm	inch	L	L ₂	d	mm	inch	£
6705960	8010 A 01	3-10	5/32-3/8	130	29	0.9	96	5	
6706180	8010 A 11	10-25	3/8-1	130	29	1.3	97	5	
6706260	8010 A 21	19-60	3/4-2.3/8	170	43	1.8	186	5	
6706340	8010 A 31	40-100	1.5/8-4	210	53	2.3	328	1	
6706930	8010 A 41	85-140	3.3/8-5.1/2	305	64	3.2	568	1	



8000 A 4 - A 6

CIRCLIP PLIERS FOR EXTERNAL RETAINING RINGS

- Straight tips
- Black, tips and lock lever zinc-plated
- The toothed bracket stops the pliers legs from straddling beyond the permitted working area
- This ensures safe working even in hidden fitting positions
- Locking pin can be replaced
- Non-crush type release-lever with handle recesses, red dip-insulated
- Forged GEDORE chrome-vanadium special hardened and tempered steel
- Precision machined, oil hardened and annealed
- E-8000 A = pair of spare tips

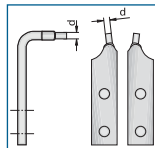

Code	No.	mm	inch	d	mm	inch	£
2011778	8000 A 4 EL	85-140	3.3/8-5.1/2	3.2	550	1921	1
6701890	8000 A 5	122-300	4.13/16-11.7/8	3.5	550	1921	1
6701970	8000 A 6	252-400	9.15/16-15.13/16	4.5	586	1922	1
2011670	E-8000 A 4 EL			3.2		72	1
5701840	E-8000 A 5			3.5		72	1
5701920	E-8000 A 6			4.5		112	1

8000 A 02 - A 42

CIRCLIP PLIERS FOR EXTERNAL RETAINING RINGS

- Similar to DIN 5254 Form B
- 45° angled tips
- With opening spring
- With clamping protection
- Forged GEDORE chrome-vanadium special hardened and tempered steel
- Precision machined, oil hardened and annealed
- Chrome-plated, with red dipped handles




Code	No.	mm	inch	L	L ₂	d	mm	inch	£
2015021	8000 A 02	3-10	5/32-3/8	139	38.0	0.9	97	5	
2015048	8000 A 12	10-25	3/8-1	139	38.0	1.3	97	5	
2015056	8000 A 22	19-60	3/4-2.3/8	179	51.0	1.8	182	5	
2015064	8000 A 32	40-100	1.5/8-4	226	65.0	2.3	317	1	
2015072	8000 A 42	85-140	3.3/8-5.1/2	315	80.5	3.2	568	1	

8000 A 41 - A 61

CIRCLIP PLIERS FOR EXTERNAL RETAINING RINGS

- 90° angled tips
- Tips and lock lever zinc-plated
- Lever handle-end red dip-insulated
- Finger protection
- Reinforced safety arms
- Forged GEDORE chrome-vanadium special hardened and tempered steel
- Precision machined, oil hardened and annealed
- E-8000 A = pair of spare tips

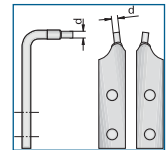

Code	No.	mm	inch	d	mm	inch	£
2011786	8000 A 41 EL	85-140	3.3/8-5.1/2	3.2	560	1898	1
6702860	8000 A 51	122-300	4.13/16-11.7/8	3.5	560	1898	1
6718430	8000 A 61	252-400	9.15/16-15.13/16	4.5	585	1953	1
2011697	E-8000 A 41 EL			3.2		72	1
5702810	E-8000 A 51			3.5		112	1
5701760	E-8000 A 61			4.5		140	1






CIRCLIP PLIERS FOR INTERNAL RETAINING RINGS (BORES)



8000 J 0 - J 4

CIRCLIP PLIERS FOR INTERNAL RETAINING RINGS Form C

- ✔ For retaining rings as per DIN 472, DIN 984
- ✔ DIN 5256 Form C
- ✔ Straight tips
- ✔ Forged GEDORE chrome-vanadium special hardened and tempered steel
- ✔ Precision machined, oil hardened and annealed
- ✔ Black, with blue dipped handles

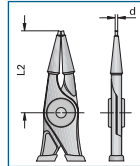


Code	No.	Ø mm	Ø inch	L	L ₂	d	↕	↔	£
6703240	8000 J 0	8-13	3/8-9/16	141	41.0	0.9	80	5	
6703320	8000 J 1	12-25	3/8-1	141	41.0	1.3	81	5	
6703400	8000 J 2	19-60	3/4-2.3/8	183	54.0	1.8	164	5	
6703590	8000 J 3	40-100	1.5/8-4	230	68.0	2.3	281	1	
6703670	8000 J 4	85-140	3.3/8-5.1/2	322	84.5	3.2	472	1	

8010 J 0 - J 4

CIRCLIP PLIERS FOR INTERNAL RETAINING RINGS Form C

- ✔ For retaining rings as per DIN 472, DIN 984
- ✔ DIN 5256 Form C
- ✔ Straight tips
- ✔ Forged GEDORE chrome-vanadium special hardened and tempered steel
- ✔ Precision machined, oil hardened and annealed
- ✔ Chrome-plated, with blue dipped handles

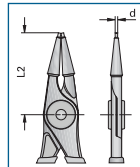


Code	No.	Ø mm	Ø inch	L	L ₂	d	↕	↔	£
6705370	8010 J 0	8-13	3/8-9/16	141	41.0	0.9	81	5	19.21
6705450	8010 J 1	12-25	3/8-1	141	41.0	1.3	80	5	19.21
6705530	8010 J 2	19-60	3/4-2.3/8	183	54.0	1.8	163	5	20.74
6705610	8010 J 3	40-100	1.5/8-4	230	68.0	2.3	281	1	36.16
6705880	8010 J 4	85-140	3.3/8-5.1/2	322	84.5	3.2	472	1	47.23

8000 J 01 - J 41

CIRCLIP PLIERS FOR INTERNAL RETAINING RINGS Form D

- ✔ For retaining rings as per DIN 472, DIN 984
- ✔ DIN 5256 Form D
- ✔ 90° angled tips
- ✔ Forged GEDORE chrome-vanadium special hardened and tempered steel
- ✔ Precision machined, oil hardened and annealed
- ✔ Black, with blue dipped handles


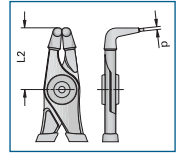


Code	No.	Ø mm	Ø inch	L	L ₂	d	↕	↔	£
6704130	8000 J 01	8-13	3/8-9/16	129	28	0.9	80	5	
6704210	8000 J 11	12-25	3/8-1	129	28	1.3	82	5	
6704480	8000 J 21	19-60	3/4-2.3/8	169	41	1.8	161	5	
6704560	8000 J 31	40-100	1.5/8-4	214	50	2.3	279	1	
6704640	8000 J 41	85-140	3.3/8-5.1/2	292	65	3.2	484	1	

8010 J 01 - J 41

CIRCLIP PLIERS FOR INTERNAL RETAINING RINGS Form D

- ✔ For retaining rings as per DIN 472, DIN 984
- ✔ DIN 5256 Form D
- ✔ 90° angled tips
- ✔ Forged GEDORE chrome-vanadium special hardened and tempered steel
- ✔ Precision machined, oil hardened and annealed
- ✔ Chrome-plated, with blue dipped handles

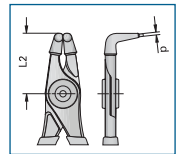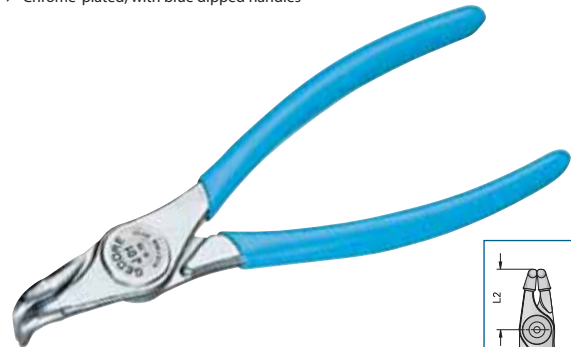

Code	No.	Ø mm	Ø inch	L	L ₂	d	↕	↔	£
6706420	8010 J 01	8-13	3/8-9/16	129	28	0.9	89	5	19.72
6706500	8010 J 11	12-25	3/8-1	129	28	1.3	81	5	19.72
6706690	8010 J 21	19-60	3/4-2.3/8	169	41	1.8	163	5	36.15
6706770	8010 J 31	40-100	1.5/8-4	214	50	2.3	282	1	36.15
6706850	8010 J 41	85-140	3.3/8-5.1/2	292	65	3.2	511	1	47.98



1500 ES-8000



104

