


MULTIBAND

Zinc Plated Mild Steel:-

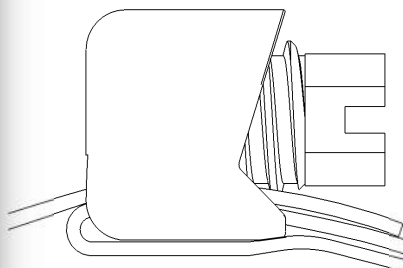

Range	Adjustment mm	Band Width mm	Band Thickness mm	Recommended Torque Nm	Maximum Torque Nm	Maximum Pressure PSI	Range
MB11MS	Cut to length	11.0	0.82	3.4	4.5	n/a	MB11MS

Component Parts for MB11MS:-



Banding in dispensers of 10m

Part No. **MB1701**

- 11mm wide
- 10 metre roll
- Zinc plated mild steel



Banding in dispensers of 30m

Part No. **MB1702**

- 11mm wide
- 30 metre roll
- Zinc plated mild steel



Housings/screws for use with 11mm Multiband

Part No. **MB1704**

- Solid housing
- 7mm A/F hexagonal screw
- Box of 25 sets
- Zinc plated mild steel



Captive housings/screws for use with 11mm Multiband

Part No. **MB1706**

- 7mm A/F hexagonal screw
- Box of 25 sets
- Zinc plated mild steel



Housings/Allen screws for use with 11mm Multiband

Part No. **MB1705**

- Solid housing
- 5/16" recess hexagonal key slot
- Box of 25 sets
- Zinc plated mild steel



Handy Pack

Part No. **MB1708**

- 11mm wide
- 10 metre roll
- 25 solid housings/screws
- Zinc plated mild steel



Pocket Pack

Part No. **MB1707**

- 11mm wide
- 3 metre roll
- 8 solid housings/screws
- Zinc plated mild steel

Corrosion Resistance: 240 hours NSS Test

Fastening: 7mm A/F screw

Industry Recommendations:-

Zinc Plated Mild Steel

The finest hose clip
in the world