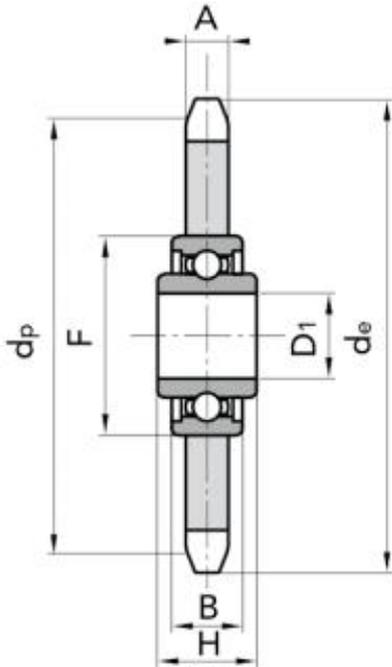
 


30012116

INA KRR-AH02-C5 - Idler sprocket

2D Technical Drawing

Dynamic 3D View

Technical Specifications

Number of teeth (T)	16
Pitch (P) mm	1/2" x 5/16"
de (DE) mm	69.5
dp (DP) mm	65.1
Part number (CODE)	30012116
A (A) mm	7.2
D1 (D1) mm	16
F (F) mm	40
B (B) mm	12
H (H) mm	18.3
Weight (WEIGHT) kg	0.17
Material (MAT)	STEEL C45