

Installation testers



Below 1000V

Voltage detectors

Voltage detectors accessories

Insulation tester

Installation testers identifier

Multimeter clamp-meter

Infrared Thermometer

Digital multimeter- Cat III 600 V

This digital multimeter is compact 3 1/2 digit. For measuring DC and AC voltage and current, resistance, continuity and temperature.

- AC frequency response: 40 - 400 HZ
- DC voltage: 200 mV/2 V/20 V/200 V/600 V
- AC voltage: 200 mV/2 V/20 V/200 V/600 V
- DC current: 200 μ A/2000 μ A/200 mA/2 A/10 A
- AC current: 200 μ A/2000 μ A/200 mA/2 A/10 A
- Resistance: 200 Ω /2 k Ω /20 k Ω / 200 k Ω /2 M Ω /20 M Ω
- Capacitance: 20 μ F 200 μ F/2 μ F/20 μ F/200 μ F/1000 μ F

General specifications

- 3 1/2 digital multimeter, 30 ranges, 70 x 50 mm LCD display, 1999 counts max.
- Back light, data hold
- Diode, triode performance testing, continuity test (audible)

General characteristics

- Battery: 3 x 1.5 V AAA batteries
- Low battery indication level on LCD
- Operation temperature: 0°C / 40°C, < 75%RH
- Storage temperature: -10°C / 50°C, < 85%RH



CE

MX-701

158 x 75 x 35 mm - Weight: 200 g

Digital clamp meter - Cat III 600 V

This digital clamp meter is compact 3 1/2 digit. Autorange for measuring DC and AC voltage, AC current, resistance, diode, continuity and temperature.

- AC current: 2 A - 600 A.
- AC voltage: 2 V - 600 V. DC voltage: 0.2 V - 600 V.
- Resistance: 200 Ω - 20 M Ω . Continuity: buzzer (< 50 Ω).
- Temperature range: -40°C/+1000°C -40°F/-1832°F.

General specifications

- Display: 3 1/2 digit LCD with a max. reading of 1999
- Polarity: auto polarity indication
- Overrange indication: "OL" or "-OL"
- Automatic zeroing function
- Sensor: clamp-shape transformer for AC measurement
- Jaw opening capability: \varnothing 36 mm
- Max. measurable conductor: \varnothing 30 mm

General characteristics

- Battery: 2 x 1.5 V AAA batteries
- Low battery indication
- Operation temperature: 0°C / 40°C, < 75% RH
- Storage temperature: -20°C / 60°C, < 85% RH




CE

MX-702

190 x 70 x 38 mm - Weight: 220 g

POINTEST™ Safety test probes for multimeter and clamp-meter

Safety test probes for multimeter and clamp-meter use only. 4 mm retractable shrouded plugs, 4 mm standard socket or 1.20 m double sheathed lead, Probes 26 mm length, 1 000 V A.C or D.C, IP2X.

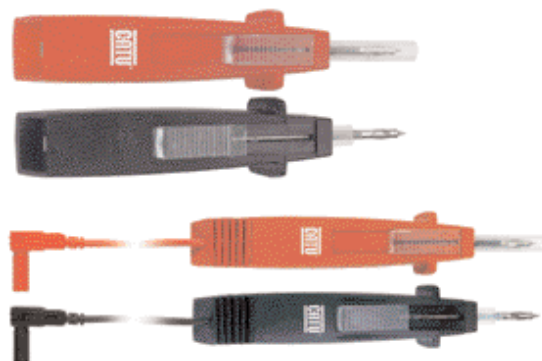

DX-02001

Set of 2 contact probes, black and red with socket

DX-02002

Set of 2 contact probes, black and red 1.20 m lead