



SITOR fuse holder 400 A 690 V 1-pole with bolt terminal with fixing dimension 80 mm

Model		
product brand name		SENTRON
product designation		LV HRC fuse system
design of the thread of the connection screw		M10
design of the product		LV HRC fuse base for screw fixing
General technical data		
number of poles		1
utilization category		Without
Supply voltage		
supply voltage		
• at AC		690 V
• at DC		690 V
Product details		
product component swivel-in mechanism		No
Connections		
tightening torque with screw-type terminals maximum		10 N·m
type of electrical connection		for mounting on mounting plate
• for main current circuit		Stud terminal
Mechanical Design		
height		111.7 mm
width		36 mm
fastening method		fixed mounting
fastening method bus-mounting		No
net weight		350 g
Approvals Certificates		
General Product Approval		other
		Environment





EG-Konf.

[Confirmation](#)

[Environmental Con-
firmations](#)

Further information	
Information on the packaging	
https://support.industry.siemens.com/cs/ww/en/view/109813875	
Information- and Downloadcenter (Catalogs, Brochures,...)	
http://www.siemens.com/lowvoltage/catalogs	
Industry Mall (Online ordering system)	
https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NH5323	
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)	
https://support.industry.siemens.com/cs/ww/en/ps/3NH5323	
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams,...)	

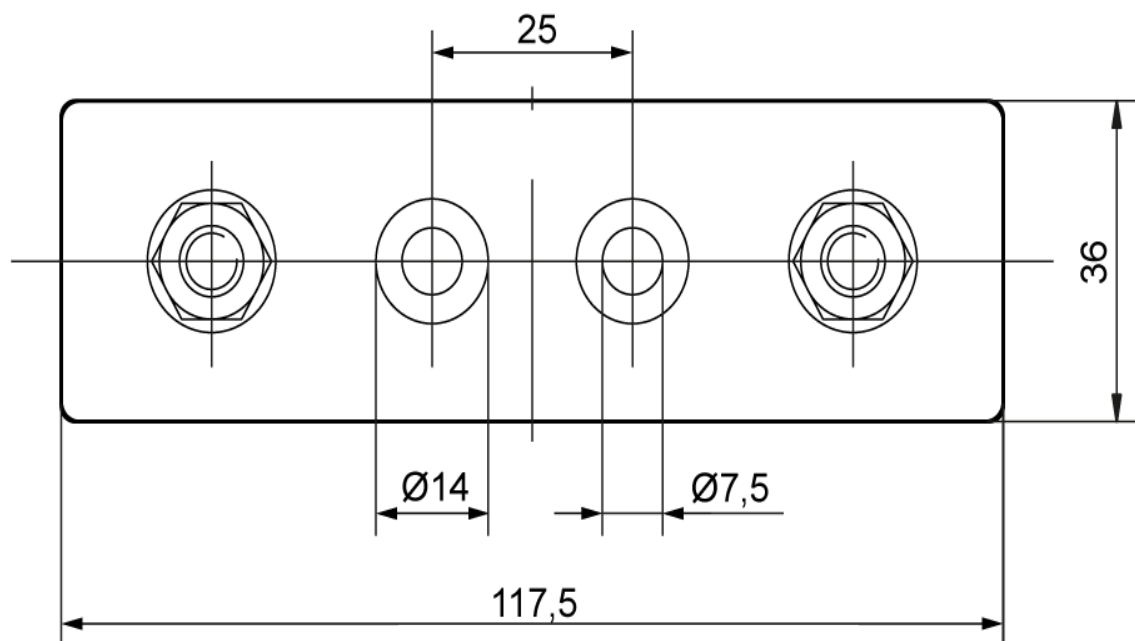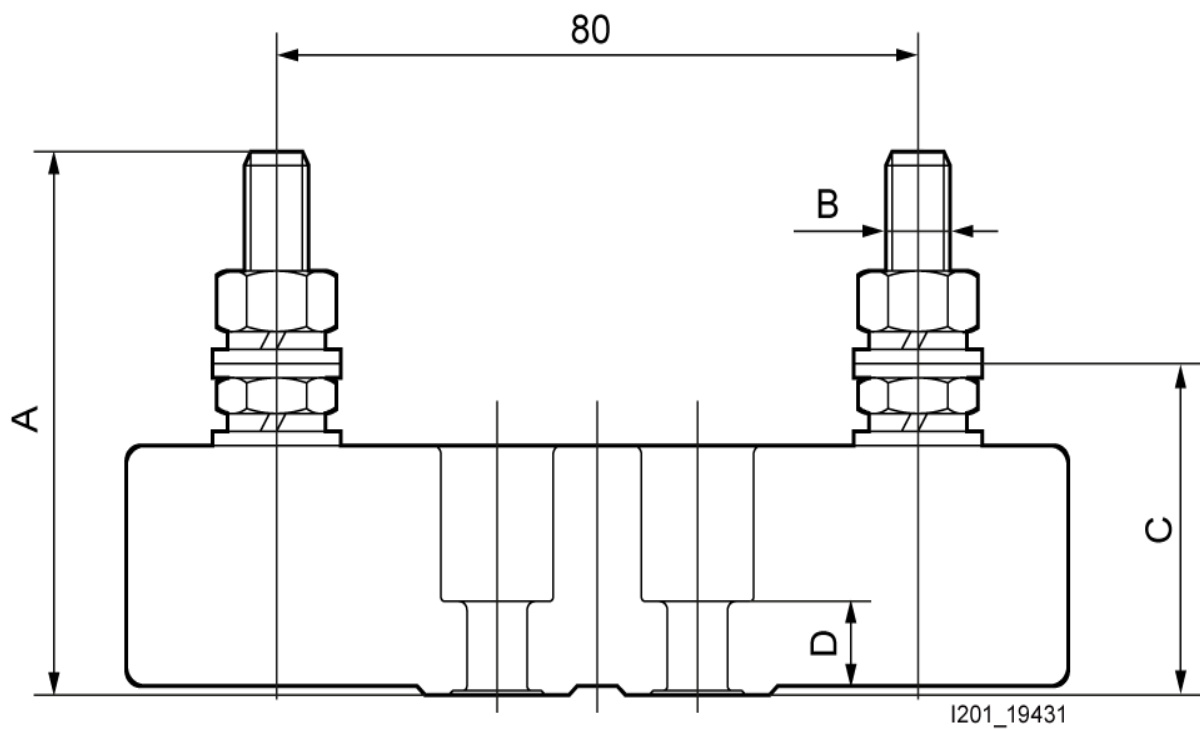

Type	Dimensions			
	A	B	C	D
3NH5023	59	M8	35,5	11
3NH5323	64	M10	38	11

