

# Printed-circuit board connector - DFK-IPCV 35 HC/ 3-GF-15,00 - 1793613

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Header, Nominal current: 125 A, Rated voltage (III/2): 1000 V, Number of positions: 3, Pitch: 15 mm, Color: green, Contact surface: Silver, Mounting: Soldering



## Why buy this product

- ✓ Inverted IPC 35 HC headers for implementing a touch-proof PCB output (in combination with IPC 35 HC plugs) or a PCB/PCB connection (in combination with PC 35 headers)
- ✓ Integrated threaded flange for screw connection with the PCB
- ✓ DFK versions for fixing in the housing panel



## Key commercial data

Packing unit	25 pc
Minimum order quantity	25 pc
GTIN	 4 046356 620949
Weight per Piece (excluding packing)	95.34 g
Custom tariff number	85366990
Country of origin	Poland
Note	Made to Order (non-returnable)

## Technical data

### Dimensions

Length	31.7 mm
Height	49.5 mm
Pitch	15 mm
Dimension a	30 mm
Pin dimensions	2,4 x 2,5 mm
Hole diameter	3.6 mm

### General

Range of articles	DFK-IPCV 35 HC/..-GF
-------------------	----------------------

# Printed-circuit board connector - DFK-IPCV 35 HC/ 3-GF-15,00 - 1793613

## Technical data

### General

Insulating material group	IIIa
Rated surge voltage (III/3)	8 kV
Rated surge voltage (III/2)	8 kV
Rated surge voltage (II/2)	8 kV
Rated voltage (III/2)	1000 V
Rated voltage (II/2)	1000 V
Nominal current $I_N$	125 A
Maximum load current	125 A
Insulating material	PBT
Inflammability class according to UL 94	V0
Color	green
Number of positions	3

## Classifications

### eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260701
eCl@ss 6.0	27260704
eCl@ss 7.0	27440402
eCl@ss 8.0	27440402

### ETIM

ETIM 4.0	EC002637
ETIM 5.0	EC002637

### UNSPSC

UNSPSC 6.01	30211810
UNSPSC 7.0901	39121409
UNSPSC 11	39121409
UNSPSC 12.01	39121409
UNSPSC 13.2	39121409

## Approvals

### Approvals

# Printed-circuit board connector - DFK-IPCV 35 HC/ 3-GF-15,00 - 1793613

## Approvals

### Approvals

UL Recognized / CCA / IEC EE CB Scheme / VDE Gutachten mit Fertigungsüberwachung / EAC

### Ex Approvals

### Approvals submitted

## Approval details

UL Recognized		
	B	C
Nominal current IN	115 A	115 A
Nominal voltage UN	600 V	600 V

CCA

IECEE CB Scheme	
Nominal current IN	125 A
Nominal voltage UN	1000 V

VDE Gutachten mit Fertigungsüberwachung	
Nominal current IN	125 A
Nominal voltage UN	1000 V

EAC

## Accessories

### Accessories

### Coding element

# Printed-circuit board connector - DFK-IPCV 35 HC/ 3-GF-15,00 - 1793613

## Accessories

Coding profile - CP-HC - 1686478



Encoding profile, 4 encoding profiles per strip, 40 strips per unit pack, for insertion in encoding grooves

Screw set - DFK-IPC 35-SS - 1703166

## Additional products


Printed-circuit board connector - IPC 35 HC/ 3-STF-15,00 - 1784800




Plug component, Nominal current: 125 A, Rated voltage (III/2): 1000 V, Number of positions: 3, Pitch: 15 mm, Connection method: Screw connection, Color: green, Contact surface: Silver

## Drawings

Drilling diagram

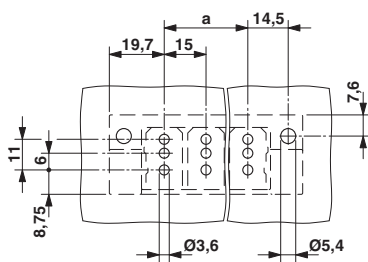

Dimensioned drawing

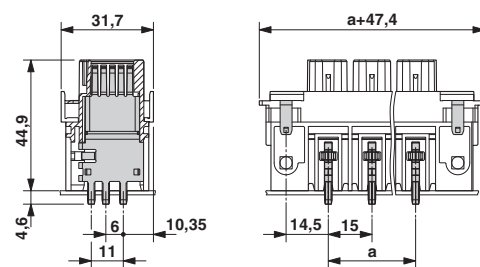

Dimensioned drawing

