




Dimensions – Diam. arbre 70-140 mm

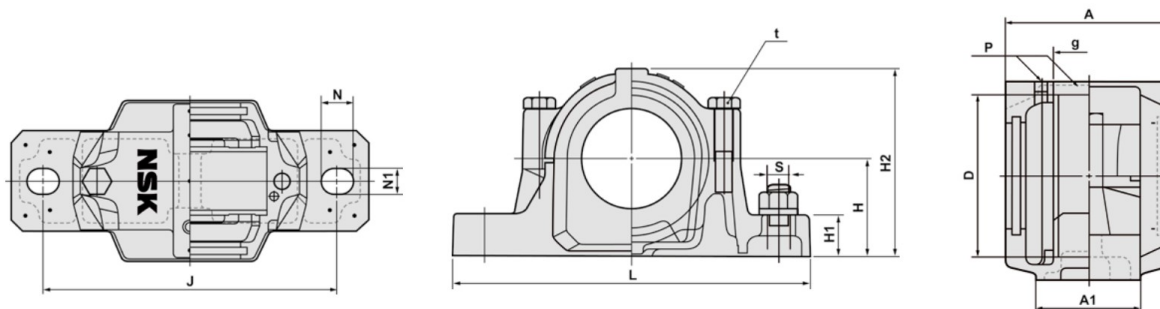


Diam. arbre D (mm)	Roulement		Manchon de serrage	Kit de bagues d'arrêt (2 bagues)	Corps de palier	Désignation du corps de palier	D (mm)	H (mm)	J (mm)	A (mm)	L (mm)	A1 (mm)	H1 (mm)	H2 (mm)	
	à billes	à rouleaux													
70	1216K	-	H216	SR140x16	SNN516	SNN516-613	140	95	260	130	315	90	32	175	
	2216K	22216K	H316	SR140x12.5											
	1316K	21316K	H316	SR170x14.5	SNN616	SNN519-616	170	112	290	145	345	100	35	210	
	2316K	22316K	H2316	SR170x5											
75	1217K	-	H217	SR150x16.5	SNN517	SNN517	150	95	260	135	320	90	32	183	
	2217K	22217K	H317	SR150x12.5											
	1317K	21317K	H317	SR180x14.5	SNN617	SNN520-617	180	112	320	160	380	110	40	215	
	2317K	22317K	H2317	SR180x5											
80	1218K	-	H218	SR160x17.5											
	2218K	22218K	H318	SR160x12.5	SNN518	SNN518-615	160	100	290	145	345	100	35	193	
	-	23218K	H2318	SR160x6.25											
	1219K	-	H219	SR170x18	SNN519	SNN519-616	170	112	290	145	345	100	35	210	
85	2219K	22219K	H319	SR170x12.5											
	1319K	21319K	H319	SR200x17.5	SNN619	SNN522-619	200	125	350	175	410	120	45	240	
	2319K	22319K	H2319	SR200x6.5											
	1220K	-	H220	SR180x18											
90	2220K	22220K	H320	SR180x12	SNN520	SNN520-617	180	112	320	160	380	110	40	215	
	-	23220K	H2320	SR180x4.75											
	1320K	21320K	H320	SR215x19.5	SNN620	SNN524-620	215	140	350	185	410	120	45	271	
	2320K	22320K	H2320	SR215x6.5											
100	1222K	-	H222	SR200x21											
	2222K	22222K	H322	SR200x13.5	SNN522	SNN522-619	200	125	350	175	410	120	45	240	
	-	23222K	H2322	SR200x5											
	-	22224K	H3124	SR215x14	SNN524	SNN524-620	215	140	350	185	410	120	45	271	
110	-	23224K	H2324	SR215x5											
	-	22226K	H3126	SR230x13	SNN526	SNN526	230	150	380	190	445	130	50	288	
	-	23226K	H2326	SR230x5											
	-	22228K	H3128	SR250x15	SNN528	SNN528	250	150	420	205	500	150	50	298	
125	-	23228K	H2328	SR250x5											
	-	22230K	H3130	SR270x16.5	SNN530	SNN530	270	160	450	220	530	160	60	322	
	-	23230K	H2330	SR270x5											
	-	22232K	H3132	SR290x17	SNN532	SNN532	290	170	470	235	550	160	60	342	
140	-	23232K	H2332	SR290x5											
	-	23232K	H2332	SR290x5											

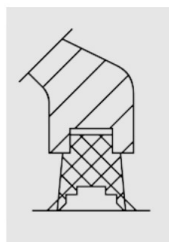


Joints de type G

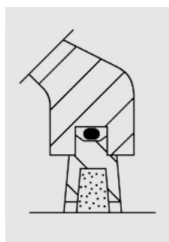


Joints de type C

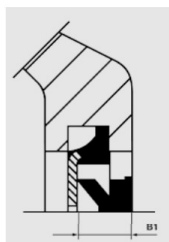

Joints de type V

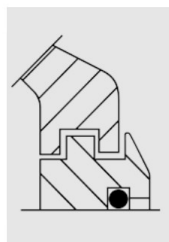

Joints de type TS-U

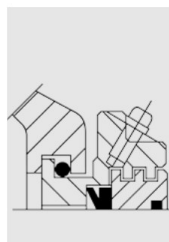

Joints de type TACK

	g (mm)	t (mm)	N (mm)	N1 (mm)	s (mm)	P	KIT joints de type G	KIT joints de type C	KIT joints de type V	Joints de type TS-U	Joints de type TACK	Obturbateur	Masse (kg)
	58	M16	28	22	M20	R1/4	G516-KIT	C516-KIT	V516-KIT (9 ±1.2)	TSS16U	TACK516	516A	10.20
	68	M16	28	22	M20	R1/4	G616-KIT	C616-KIT	V616-KIT (9 ±1.2)	TS616U	TACK616	519A	14.50
	61	M16	28	22	M20	R1/4	G517-KIT	C517-KIT	V517-KIT (9 ±1.2)	TSS17U	TACK517	517A	11.20
	70	M20	32	22	M24	R1/4	G617-KIT	C617-KIT	V617-KIT (9 ±1.2)	TS617U	TACK617	520A	18.30
	65	M16	28	26	M20	R1/4	G518-KIT	C518-KIT	V518-KIT (9 ±1.2)	TSS18U	TACK518	518A	13.00
	68	M16	28	22	M20	R1/4	G519-KIT	C519-KIT	V519-KIT (9 ±1.2)	TSS19U	TACK519	519A	14.50
	80	M20	32	26	M24	R1/4	G619-KIT	C619-KIT	V619-KIT (9 ±1.2)	TS619U	TACK619	522A	24.00
	70	M20	32	26	M24	R1/4	G520-KIT	C520-KIT	V520-KIT (9 ±1.2)	TSS20U	TACK520	520A	18.30
	86	M20	32	26	M24	R3/8	G620-KIT	C620-KIT	V620-KIT (9 ±1.2)	TS620U	TACK620	524A	26.20
	80	M20	32	26	M24	R1/4	G522-KIT	C522-KIT	V522-KIT (9 ±1.2)	TSS22U	TACK522	522A	24.00
	86	M20	32	26	M24	R3/8	G524-KIT	C524-KIT	V524-KIT (9 ±1.2)	TSS24U	TACK524	524A	26.20
	90	M24	35	28	M24	R3/8	G526-KIT	C526-KIT	V526-KIT (9 ±1.2)	TSS26U	TACK526	526A	33.00
	98	M24	42	35	M30	R3/8	G528-KIT	C528-KIT	V528-KIT (9 ±1.2)	TSS28U	TACK528	528A	40.00
	106	M24	42	35	M30	R3/8	G530-KIT	C530-KIT	V530-KIT (9 ±1.2)	TSS30U	TACK530	530A	49.00
	114	M24	42	35	M30	R3/8	G532-KIT	C532-KIT	V532-KIT (9 ±1.2)	TSS32U	TACK532	532A	55.00