



**Part No.** 103202154

**Series** Series 320 eSafe, DN 7.6

3D

PDF

Inquiry List

<b>Category title</b>
eSafe vented safety coupling
<b>Class title</b>
Male thread
<b>Connection</b>
R 3/8"
<b>Connection type</b>
Standard quick couplings
<b>Nominal flow diameter (mm)</b>
7.6 mm (0.3")
<b>Air flow (l/min)</b>
2250 l/min (79.4 CFM)
<b>Max working pressure (bar)</b>
16 bar (232 PSI)

---

**Min. burst pressure (bar)**

140 bar (2030 PSI)

---

**Connection force (N)**

102 N

---

**Min temperature (C)**

-20°C — +100°C (-4°F — +212°F)

---

**Material standard**

Steel/Aluminum

---

**Nipple standard**

CEJN original eurostandard 7.4 mm


---

## Series 320 eSafe, DN 7.6

CEJN Original, Eurostandard | Soft-line

eSafe Series 320 coupling is an easy-to-handle high performing coupling with a long service life. eSafe is a one hand operated safety coupling that vents before disconnection eliminating the risk of hose whip. Male threads on the couplings and nipples feature pre-applied thread sealant. The couplings have a smaller outside dimension than comparable designs. Full automatic operation ensures easy handling. eSafe complies with ISO Standard 4414.



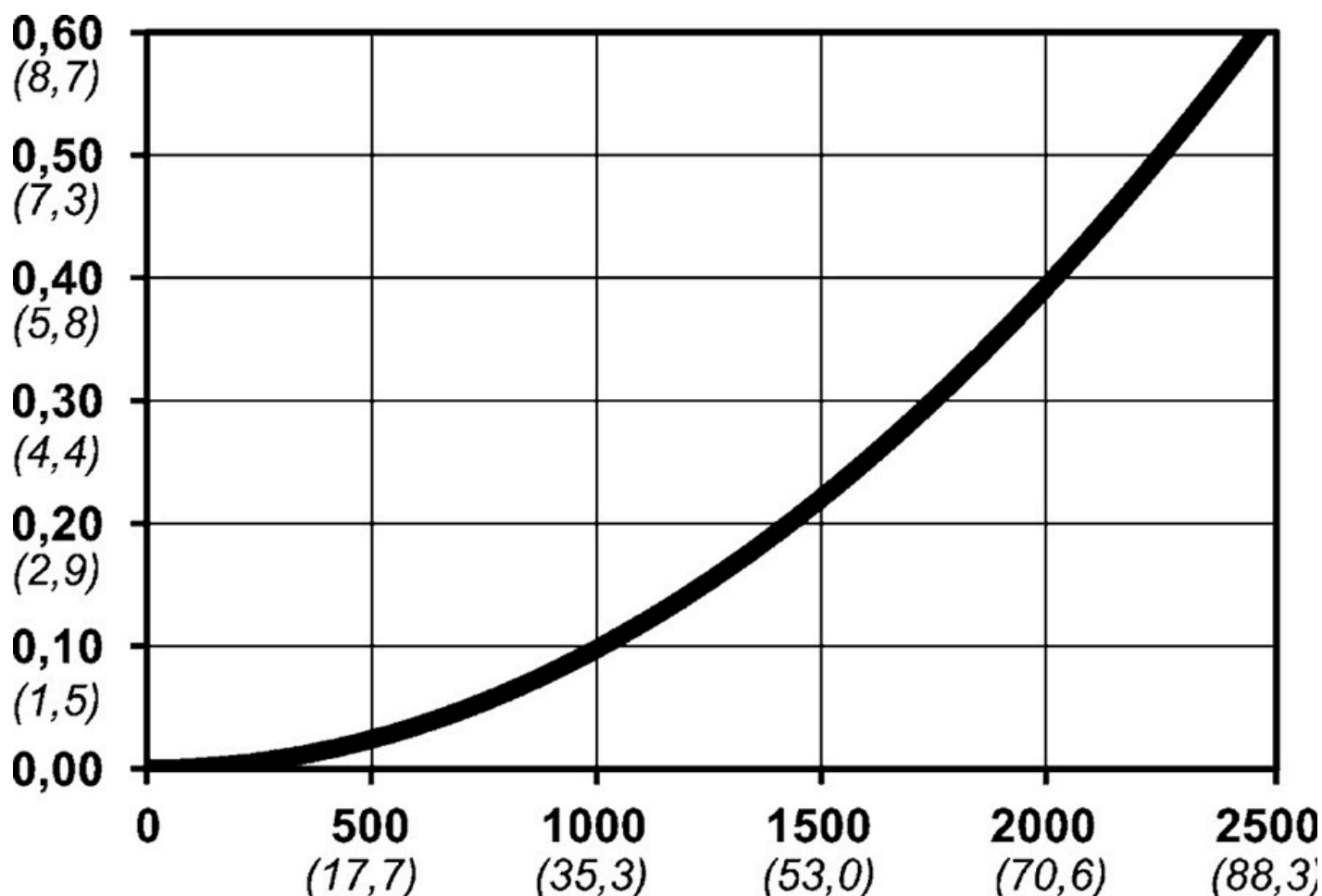

#### Air Flow

x: Chart flow l/min (CFM)

y: Chart pressure drop bar (PSI)

Check with an authorized CEJN distributor for availability and prices. All measurements are in mm. Other connections and sealing material on request. Some part numbers may be subject to minimum order quantities. CEJN reserves the right to make changes without further notification. Thread connections are listed according to ISO standards, unless stated otherwise.