


Features

- Smooth, 45° angled long-nose pliers with rounded outer edges. Good visibility of the work area thanks to its special shape. Ideal for gripping components in hard-to-reach areas and for delicate electronics applications.
- Steel thickness 2 mm.
- Pliers are equipped with a return spring designed to have a constant force, thus reducing operator effort.
- Ergonomic anti-slip bicomponent handle for a safe, light and comfortable grip
- Anti-reflection phosphating surface treatment.
- ESD safe version.
- Laser marking.
- Made in Italy.

RS PRO ESD 45° angled long-nose pliers. Micro head.

RS Stock No.: (0429685)

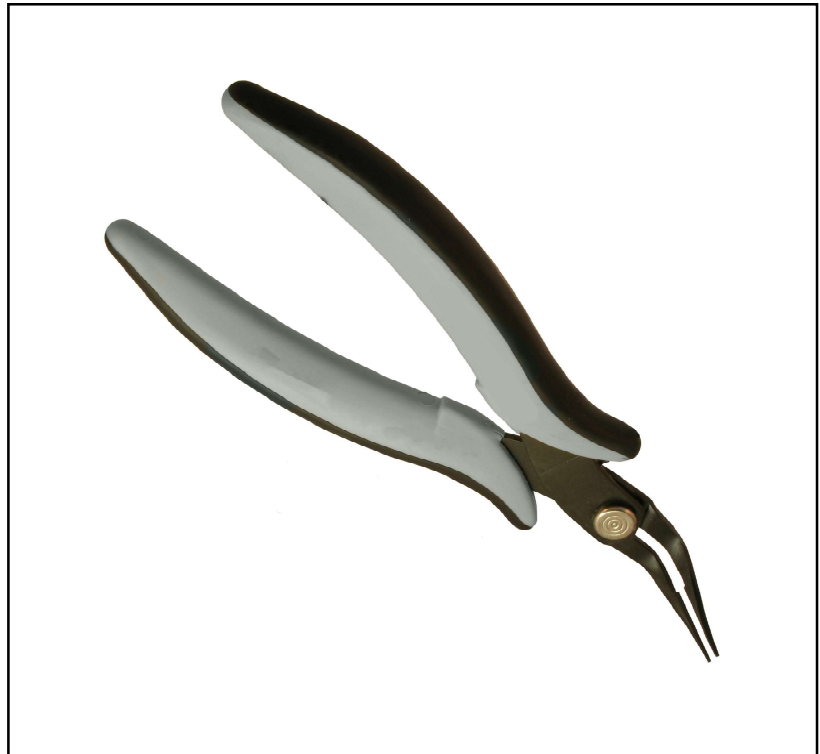

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

- Made in Italy with high carbon steel and undergo a controlled atmosphere heat treatment.
- The anti-reflection phosphating surface treatment ensures an accurate view of the work being carried out.
- The tools are joined with grounded holes and surfaces, thereby allowing precise movements.
- The anti-slip bi-material dolphin handle is created following ergonomic principles, thus guaranteeing a safe, light and comfortable grip for the operator even when used constantly for many hours.
- This plier is ideal for different applications in microelectronics, jewellery making, laboratory, watch making and repairs, DIY.
- ESD-safe version.

General Specifications

Plier Type	Bent-nose pliers. Micro head.
Tip Style	45° angled, rounded outside
Serrated internally	NO
Material	High carbon steel
ESD Safe	YES. Standard IEC 61340-5-1

Mechanical Specifications

Steel thickness	2 mm
Hardness	Hrc 48-50
Length of the head	16 mm
Overall Length	147 mm
Weight	64 g

