

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0151360802](#)  
**Status:** **Active**  
**Overview:** MicroClasp™ Wire-to-Board System  
**Description:** MicroClasp™-to-MicroClasp™ Off-the-Shelf (OTS) Cable Assembly, Single Row, 150.00mm Length, 8 Circuits, White

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Cable Assemblies
Series	<a href="#">15136</a>
Assembly Configuration	Dual Ended Connectors
Connector to Connector	MicroClasp™-to-MicroClasp™
Overview	<a href="#">MicroClasp™ Wire-to-Board System</a>
Product Name	MicroClasp™ OTS
UPC	191128149297

**Physical**

Cable Length	150.00mm
Circuits (Loaded)	8
Color - Resin	White
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	6.919/g
Packaging Type	Bag
Pitch - Mating Interface	2.00mm
Plating min - Mating	0.889µm
Plating min - Termination	0.914µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.28mm
Wire Size AWG	22
Wire/Cable Type	UL 1061


**Electrical**

Current - Maximum per Contact	3.0A
Voltage - Maximum	250V AC (RMS)/DC

**Material Info**

**Reference - Drawing Numbers**

Sales Drawing	2012341711-000
---------------	----------------

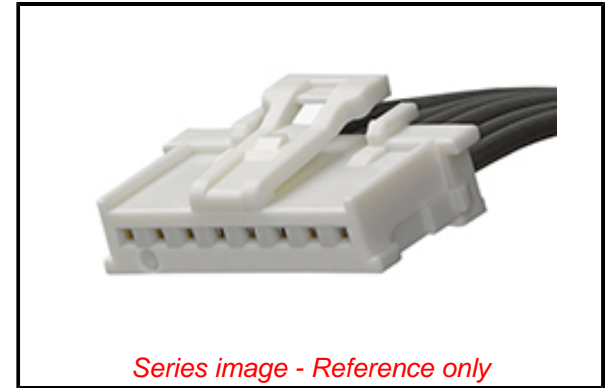

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
-ED/01/2017 (12  
January 2017)

**Halogen-Free**

**Status**

**Not Low-Halogen**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[15136 Series](#)

**Mates With**

[55932 Vertical Header](#), [55935 Right Angle Header](#)