
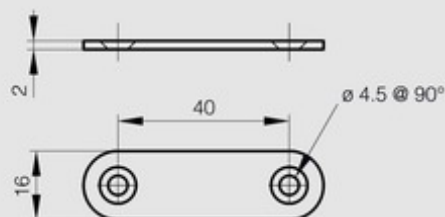


Screw-on magnetic catches with counterplate - force 4 kg - high temperature resistance

Model : 16-7-3494

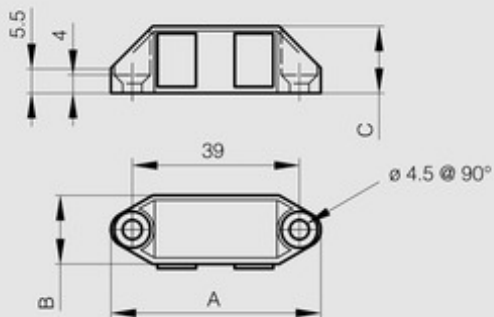

Material	zinc die-cast
Finish	nickel plated
A (length)	49.4
B (width)	16.4
C	15.6
Weight (g)	56
Opening type	swinging
Locking option	magnetic
Note	temperature up to 80°C
Material	zinc die-cast
Latching system	catch
Force	4kg