


Datasheet

RS Pro 10 Way Unscreened Flat Ribbon Cable, 13 mm Width, 10m

RS Stock No: **214-0661**

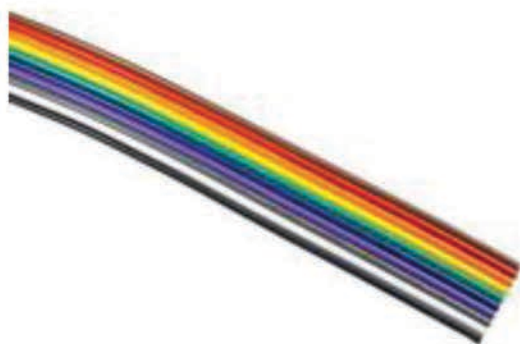

Product Details

RS Pro 10-way unscreened flat ribbon cable measures 13 mm x 10 m. It consists of parallel stranded tinned copper wire conductors laminated between layers of grey PVC film. The cable one edge has a red marker to indicate the first conductor and the laminate ensures precise alignment and spacing between conductors, essential during assembly with the connectors. It is suitable for use on computers, peripherals and interface units, audio and digital equipment.

Features and Benefits

- Consists of parallel stranded tinned copper wire conductors laminated between layers of grey PVC film to form a flat ribbon cable

Specifications:

American Wire Gauge	26 AWG
Cable Shape	Ribbon
Capacitance	50 pF/m
Characteristic Impedance	100 Ω
Conductor Strand Type	Stranded
Core Strands	7/0.15 mm
Maximum Operating Temperature	+105°C
Minimum Operating Temperature	-20°C
Number of Strands	7
Number of Ways	10
Operating Temperature Range	-20 to +105°C
Pitch	1.27 mm
Reel Length	10 m
Screened/Unscreened	Unscreened
Sheath Colour	Multicoloured
Size of Strands	0.15 mm
Standards Met	UL 1007
Voltage Rating	300 V dc
Width	13 mm