

Single row shrouded headers

INTERCOM

FEATURES

Pitch 2.54 mm
Conforms to HE13, HE14,
IEC 603-8

TECHNICAL DATA

Technical data
Material
Housing: Black thermoplastic
GF UL94 V0
High temperature
Contact: phosphor bronze.

Electrical

Current rating: 4 A maxi.
Voltage: 1000 V eff.
Insulation resistance:
1x10⁴ MΩ mini.


Mechanical

Temperature rating:
-55°C to +125°C
Pc board Hole diameter Ø 1 mm.

PACKAGING

Recyclable cardboard boxes.

Matches with the following
connectors:
4783220; 4853401.

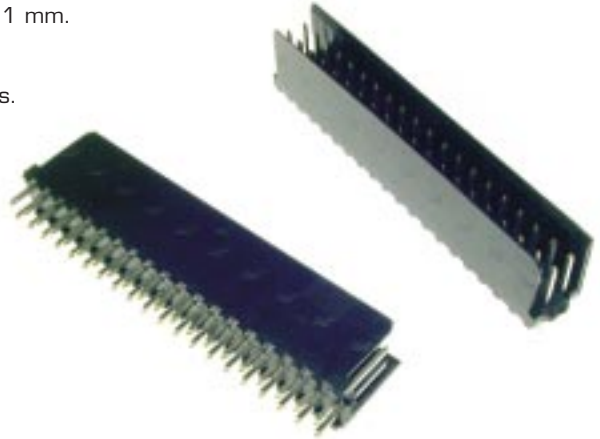

a	b	c	d	e	
475	1848	1	xx	4x0	- 1

d Number of contacts
from 04 to 26

e Plating
0 Gold plating
0.2 µm over Ni 1.27 µm
4 Tin plated 4 µm over Ni 1.27 µm
7 Selective Gold plating
0.2 µm over Ni 1.27 µm
Other plating upon request

