


TEK1119-N & TEK1138-N BORDER DETAIL


LABEL CUT TO DOTTED LINE

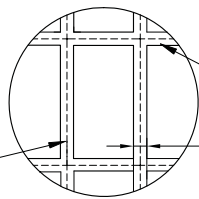

2.0 [0.079]

SCREEN PRINT 2mm LINE
(1mm EITHER SIDE OF LABEL EDGE)

98.5 [3.880]

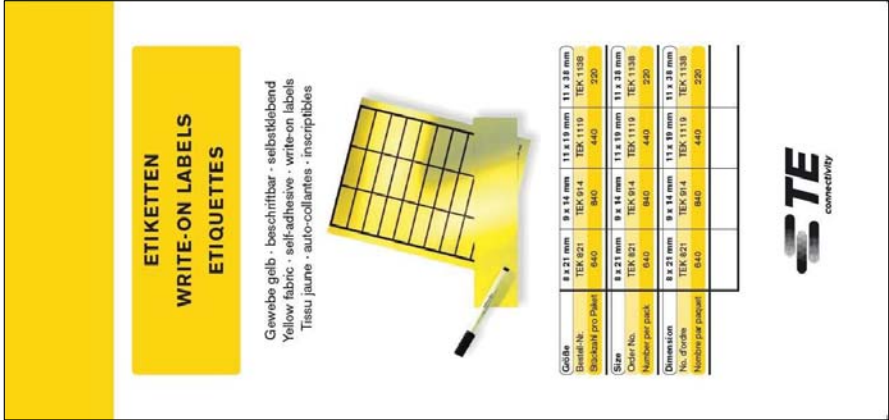

Größe	8 x 21 mm	8 x 14 mm	11 x 19 mm	11 x 38 mm
Bestell-Nr.	TEK 821	TEK 914	TEK 1119	TEK 1138
Stockart pro Paket	840	840	440	220
Size	8 x 21 mm	8 x 14 mm	11 x 19 mm	11 x 38 mm
Order No.	TEK 821	TEK 914	TEK 1119	TEK 1138
Number per pack	840	840	440	220
Dimensions	8 x 21 mm	8 x 14 mm	11 x 19 mm	11 x 38 mm
No. d'ordre	TEK 821	TEK 914	TEK 1119	TEK 1138
Nombre par paquet	840	840	440	220



85.6 [3.370]

185.0 [7.280]

19.0 [0.748]

11.0 [0.433]

196.0 [7.720]

BOOKLET PRESENTATION

EXAMPLE LABEL PRESENTATION TEK1119-N

All dimensions in mm [INCHES]

DESCRIPTION	PART NUMBER	LABELS PER BOOK	LABELS PER PAGE	PAGES PER BOOK	LABEL HEIGHT		BLACK BORDER	WEIGHT (g)
					mm	Inch		
TEK1119-N	4-1768048-5	440	44	10	11.0	0.430	YES	0.11
TEK1138-N	4-1768048-9	220	22	10	11.0	0.430	YES	0.22
TEK821-N	5-1768048-3	640	64	10	8.0	0.315	NO	0.07
TEK914-N	5-1768048-6	840	84	10	9.0	0.354	NO	0.05

TOLERANCES mm [INCHES]		THIS DRAWING IS A CONTROLLED DOCUMENT.		DIMENSIONS: mm [INCHES]		TOLERANCES UNLESS OTHERWISE SPECIFIED		DRAWING NO		CUSTOMER DRAWING	
LABEL HEIGHT	±0.3 [±0.012]		M. NUTTALL	17SEP2021	A40	KEAN	TTDS-181	—	A2	C2290	TEK-TABULATED-CD
LABEL WIDTH	±0.3 [±0.012]										
WEB WIDTH	±0.8 [±0.031]										
VERTICAL REPEAT	±0.8 [±0.031]										
HORIZONTAL REPEAT	±0.8 [±0.031]										
PRINT POSITIONING	±0.8 [±0.031]										
LEFT MARGIN	±0.4 [±0.016]	DIMENSIONS: mm [INCHES]		TOLERANCES UNLESS OTHERWISE SPECIFIED		DRAWING NO		CUSTOMER DRAWING			
QUANTITY: ±0.12.2	±0.4 [±0.016]	MATERIAL		MATERIAL		MATERIAL		MATERIAL			
*NON ACCUMULATING	±0.4 [±0.016]	YELLOW FABRIC PVC		YELLOW FABRIC PVC		YELLOW FABRIC PVC		YELLOW FABRIC PVC			