

Features

- 2.5M Long
- IEC53(YZ)3X1:00 (Rubber Cable)
- Black Colour
- IEC C15 female PRC/3 Plug GB 2099 GB 1002

RS PRO 2.5m Power Cable C15 to PRC/3 16A-250 V

RS Stock No: 0558967



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

- RS Pro power cable assembly in black colour with length 2.5 meters. The product withstands current up to 10 Amps. This IEC cable assembly has a fully moulded Chinese PRC/3 GB 2099 GB 1002 plug on one end and fully moulded C15M socket on the other end. The C15 IEC cord is designed for use in high temperature power applications such as Data- centres, server cabinets etc.

General Specifications

Connector A	C15, IEC Straight female, EN /IEC 60320 /C15
Connector B	Chinese PRC/3 GB 2099 GB 1002 Straight male, IEC 60884
Power Cord Rating	10A- 250V
Sheath Colour	Black

Mechanical Specifications

Length	2.5 meters
--------	------------

Electrical Specifications


Power Cord Rating	10A- 250v
Visual Inspection	100%
Electrical Testing	100%
High pot test wire to wire	3.00Vac. for 2 sec.
Continuity Test	25Aac to grounding /20Aac to line and neutral
Polarity Test	Yes
Skin High Pot test	6:000 line to skin

Protection Category

Environmental Conformity	EU-Directive 2002/96/EC (WEEE)
	Eu-Directive 2003/11/EC (Council Directive 76/769/EEC)
	Eu-Directive 2002/95/EC (R)

Approvals

C15M Connector	CE, UKCA, ENEC
Chinese PRC/3 GB 2099 GB 1002	CCC
Cable	Harmonized <HAR>

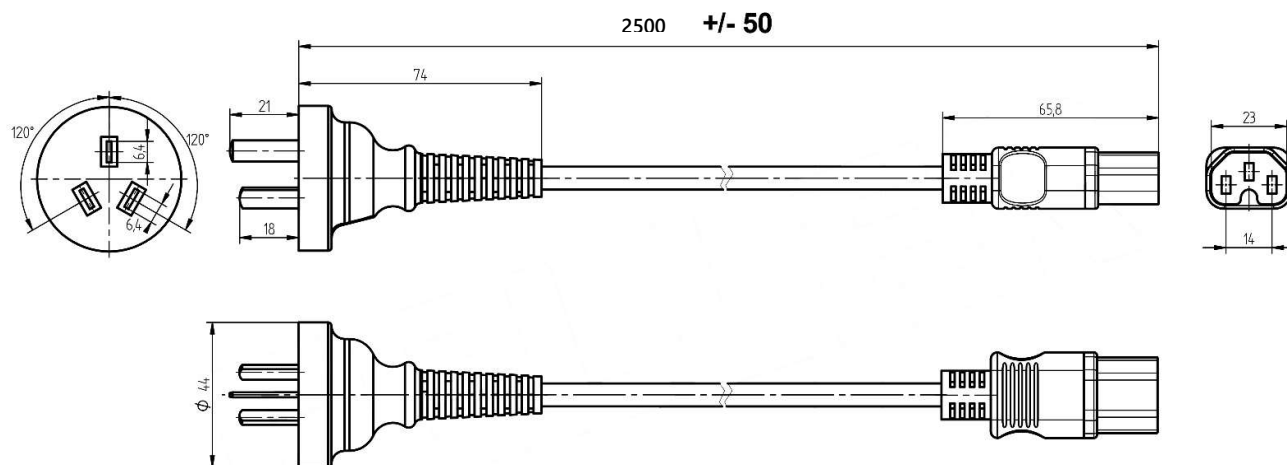

All dimensions in mm