


159634 LFR-1/8-D-MINI-A filter regulator - Series: All

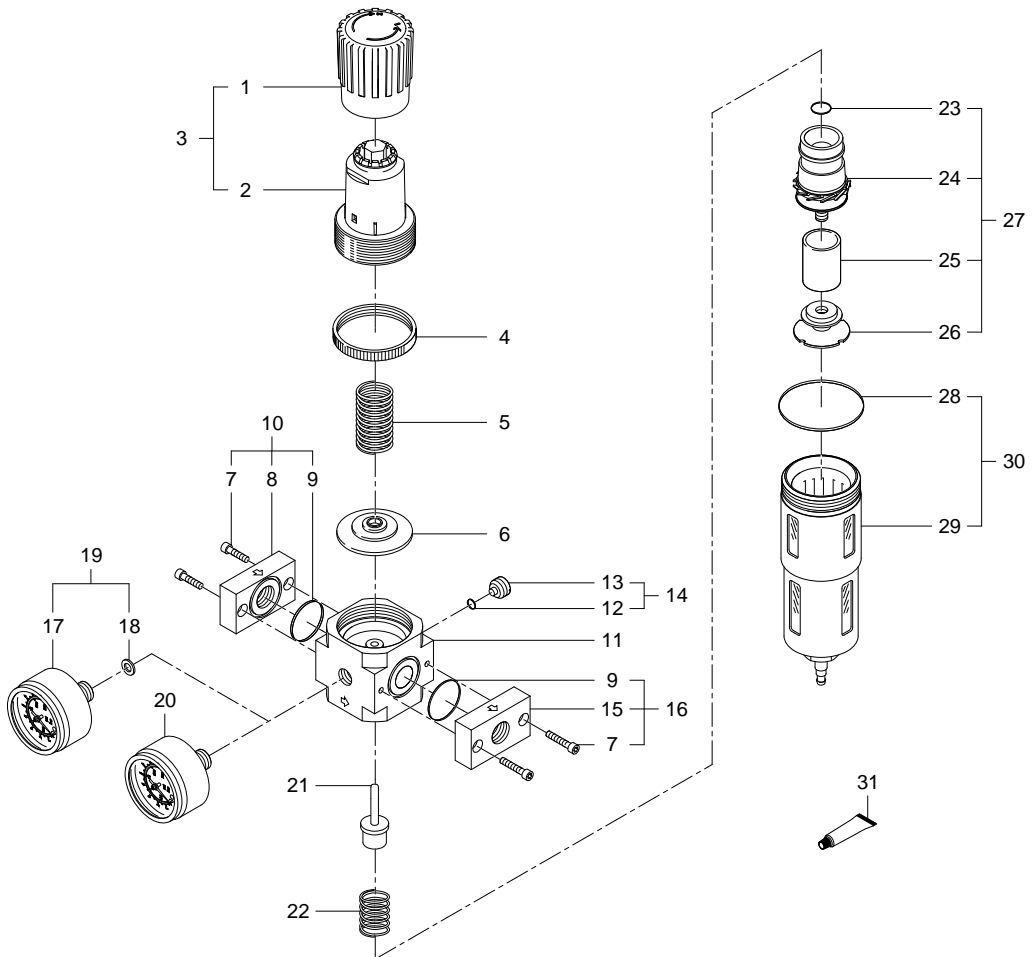

159634 LFR-1/8-D-MINI-A filter regulator - Series: All

Pos.	Part no.	Type	Note	Qty.	Unit
A	394864	LFR-1/8-...-D-MINI Set of wearing parts	Spare parts: 6, 9, 21, 28	1	PC
1		LR/LFR-...-D-MINI Adjusting knob	Not available separately, see position 3	1	PC
2		LR/LFR-D-MINI Cover module	Not available separately, see position 3 Tightening torque 10 Nm / 7.4 lbf ft	1	PC
3	655460	LR/LFR-...-D-MINI Adjusting knob	Position available until max. 12/31/2030!	1	PC
4	398011	LRVS-D-MINI M36X1,5 Knurled nut		1	PC
5	353517	LR-LFR-...-D-MINI Compression spring	Position available until max. 12/31/2028!	1	PC
6	385776	LR/LFR-...-D-MINI Diaphragm module	Use Festo special oil OFSW-32 here	1	PC
7	200664	ISO 4762-M4X16-8.8 Socket head screw	Tightening torque 2 Nm / 1.5 lbf ft	4	PC
8		PBL-1/8-D-MINI-L Sub-base	Not available separately, see position 10	1	PC
9	235260	B-12,42X1,78-N-NBR70 O-ring ISO3601		2	PC
10	546495	PBL-1/8-D-MINI-L Sub-base	Position available until max. 12/31/2030!	1	PC
11		LFR/LR-D-MINI Housing module	Not available	1	PC
12	229420	B-4X1,2-N-NBR75 O-ring ISO3601		1	PC
13		LR/LFR-...-D-MINI Plug screw	Not available separately, see position 14 Tightening torque 1.5 Nm / 1.1 lbf ft	1	PC
14	741045	LR/LFR-1/8-D-MINI-ET Plug screw	Position available until max. 12/31/2028!	1	PC
15		PBL-1/8-D-MINI-R Sub-base	Not available separately, see position 16	1	PC
16	546496	PBL-1/8-D-MINI-R Sub-base	Position available until max. 12/31/2030!	1	PC
17			Not available separately, see position 19	1	PC
18	382523	MA -40-...-1/8 Sealing ring		1	PC
19	345395	MA-40-16-1/8 Pressure gauge		1	PC
20	8003637	PAGN-40-16-G18 Pressure gauge		1	PC
21	381354	LR/LFR-...-D-MINI Disc seat valve	Grease using during assembly. See position 31	1	PC
22	702513	LFR/LR/LRB-D-MINI Compression spring		1	PC
23		B-4,48X1,74-N-NBR70 O-ring ISO3601	Not available separately, see position 27 Grease using during assembly. See position 28	1	PC
24		LF/LFR-D-MINI Filter mounting	Not available separately, see position 27	1	PC
25	363665	LFP-D-MINI-40M Filter cartridge		1	PC
26		LF/LFR-D-MINI Separating disc	Not available separately, see position 27 Tightening torque 0.4 Nm / 0.3 lbf ft	1	PC
27	739609	LFR-D-MINI Filter mounting	Tightening torque 3 Nm / 2.2 lbf ft Position available until max. 12/31/2030!	1	PC

Pos.	Part no.	Type	Note	Qty.	Unit
28	215324	B-33X2-N-NBR75 O-ring ISO3601	Use Festo special oil OFSW-32 here	1	PC
29		LF/LFR-D-MINI-A Filter bowl	Not available separately, see position 30 Tightening torque 2 Nm / 1.5 lbf ft	1	PC
30	646227	LF/LFR-D-MINI-A:SP Filter bowl		1	PC
31	397446	LUB-KB2-SILIKONFREI-20ML Lubricating grease		1	PC