


Technical data

KH5070

Ball sleeves



VISUAL (S)

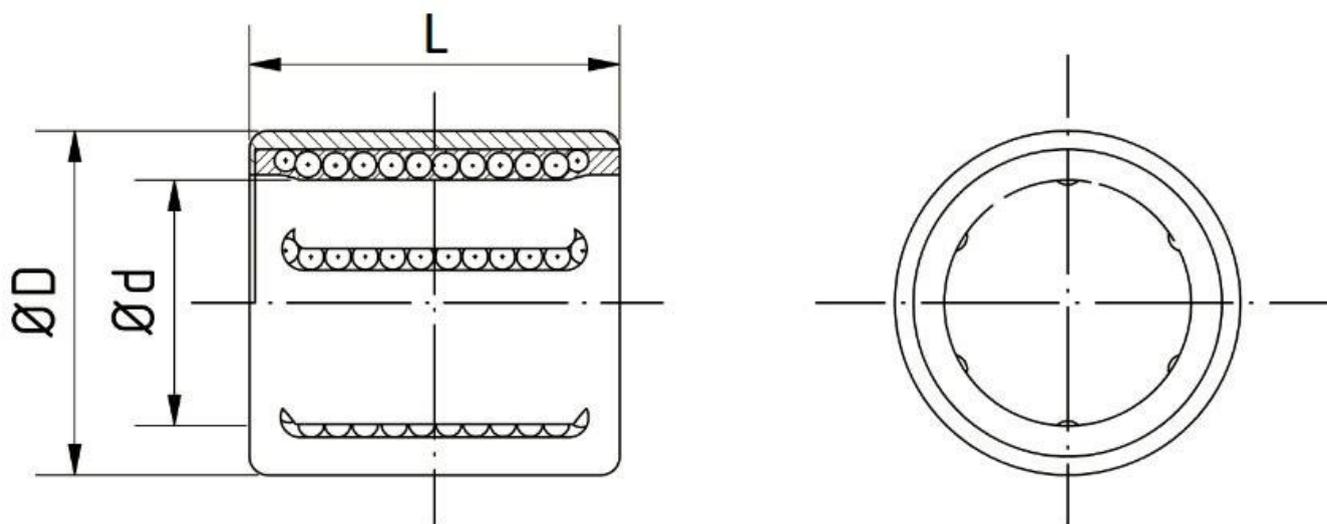

PRODUCT DEFINITION

Brand	NTN
Design type	KH
Ball bushings category	Ball sleeves
Standard	ISO dimension
Material outer cylinder or steel segments	hardened steel sleeve
Material Cage	PA
Initial greasing	Non/No
Re-lubricable	Oui/Yes
d - Internal diameter	50 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

D - External diameter	62 mm
L - Length	70 mm
Number of ball rows	9
Mass	0,24 kg

PRODUCT PERFORMANCE

Cmin	5300000 mN
Cmax	5300000 mN
C0min	5700000 mN
C0max	5700000 mN
Tmin - Min operating temperature	253,15 °K
Tmax - Max operating temperature	353,15 °K

