


JLS2- Power leg - High version 1025mm

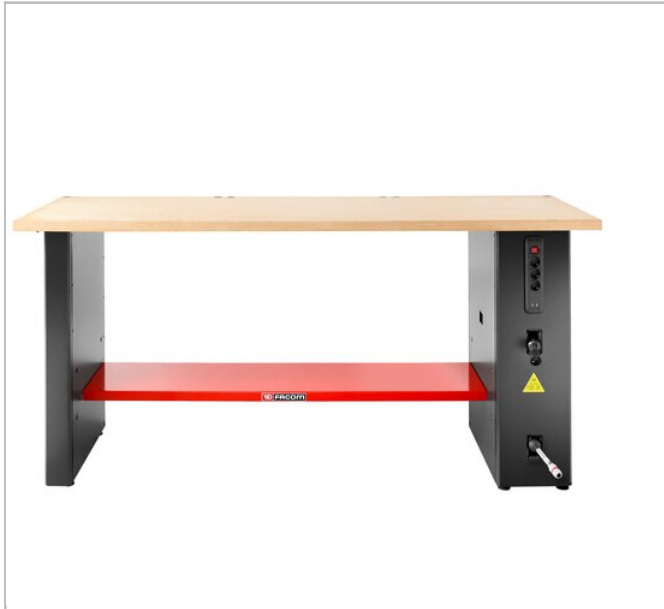

Description:

- 3-in-1 Power solution : power strip, electrical and compressed air reels in one unit
- 1 power strip with on-off switch : 3 SCHUKO sockets and 2 USB ports. Plug in power tools, drills, chargers, lights, electronics, smartphones and anything else you've got with an easy access.
- 1 professional 14 meters cable reels for power supply. Length 14 + 1 m, cable 3 x 1.5 mm², quality H05W-F, maximum power wound 1200 W, unwound 1800 W.
- 1 professional 14 meters cable reels for compressed air : length 14 + 1 m, internal diameter 10 mm, polyurethane hose, 3/8 NPT outlet (N.709 Facom).
- Roller guides for smooth cables extension & extraction.
- Open access for rearming .
- Delivered without plug to let you use what you need depending on your country.
- Fitted with 4 jack feet for an adjustment, ensuring perfect stability regardless of the type of floor.
- Heavy duty 1.2mm steel construction. High quality durable powder coating finish.



JLS2-PSHPOWER