


# Glass Pocket Test

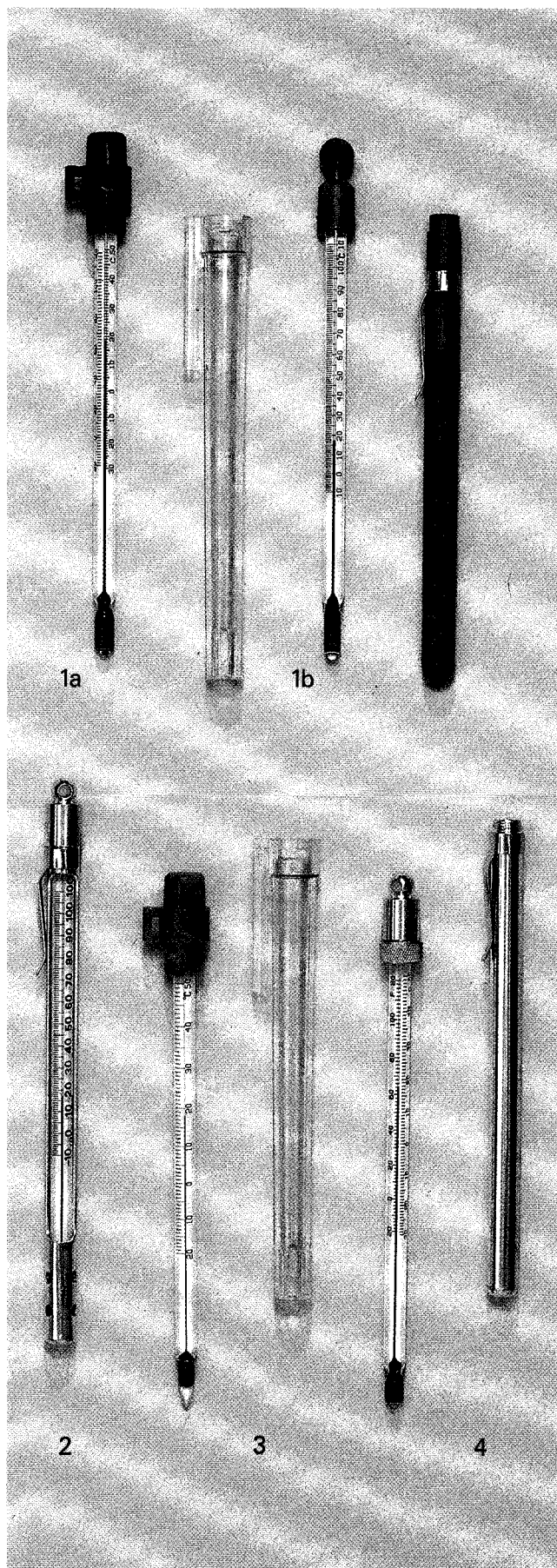

**1a & 1b. 155mm Test Thermometers.** Mercury or red spirit tubes. Total immersion. Clear plastic reversible, or blue plastic cases, with pocket clip.

Range	Filling	Product No.	
		Clear Case	Blue Case
-5/105C & 20/220F	Spirit	17/346/3	17/746/3
-10/110C	Spirit	17/346/2	17/746/2
-30/50C & -20/120F	Spirit	22/363/3	22/763/3
-30/50C	Spirit	22/363/2	22/763/2
-40/40C	Spirit	22/563/2	22/663/2
0/40C & 30/104F	Spirit	22/573/3	22/773/3
0/40C	Spirit	22/573/2	22/773/2
-10/110C	Mercury	17/246/2	17/846/2
-30/50C	Mercury	22/463/2	22/863/2

**2. 155mm Test Thermometers.** Mercury or red spirit tubes. Total immersion. Slot front open armour aluminium cases with pocket clip.

Range	Filling	Complete	Refill
-5/105C & 20/220F	Spirit	17/347/3	17/548/3
-10/110C	Spirit	17/347/2	17/548/2
-30/50C & -20/120F	Spirit	22/362/3	22/562/3
-30/50C	Spirit	22/362/2	22/562/2
0/40C	Spirit	22/372/2	22/572/2
-10/110C	Mercury	17/247/2	17/447/2
-30/50C	Mercury	22/462/2	22/662/2

**3. 155mm Spike End Bulb Test Thermometers.** Red spirit tubes. Total immersion. Plastic reversible cases with pocket clip.

Range	Filling	Product No.
-20/40C	Spirit	17/350/2
0/100F	Spirit	17/350/1

**4. 155mm Test Thermometers.** Mercury or red spirit tubes. Total immersion. Heavy duty metal cases with pocket clip.

Range	Filling	Complete	Refill
-5/105C & 20/220F	Spirit	17/348/3	17/548/3
-10/110C	Spirit	17/348/2	17/548/2
-30/50C & -20/120F	Spirit	22/348/3	22/548/3
-30/50C	Spirit	22/348/2	22/548/2
-10/110C	Mercury	17/248/2	17/448/2
-30/50C	Mercury	22/248/2	22/448/2