



Datasheet

RS PRO Grey PVC Open Slotted Trunking


Stock number: 758-9305 758-9244 758-9314 758-9248
879-3735 879-3753

EN




SPECIFICATION

- **Material:** High impact, warp-proof PVC , self-extinguishing .
- **UL approved 94V-0.**
- **Color:** Grey
- **Maximum service temperature:** 85°C
- **Test to UL file E97527 up to 50°C.**
- **Supplied complete with cover.**
- **These devices are for routing of wires within devices in factory installations.**
- **Features parallel holes on both sidewalls to facilitate cutting in wire application.**
- **Easy to insert, adding or removing wires - even with terminations attached.**
- **Save your total cost for during installation, wire tracing and circuit troubleshooting.**

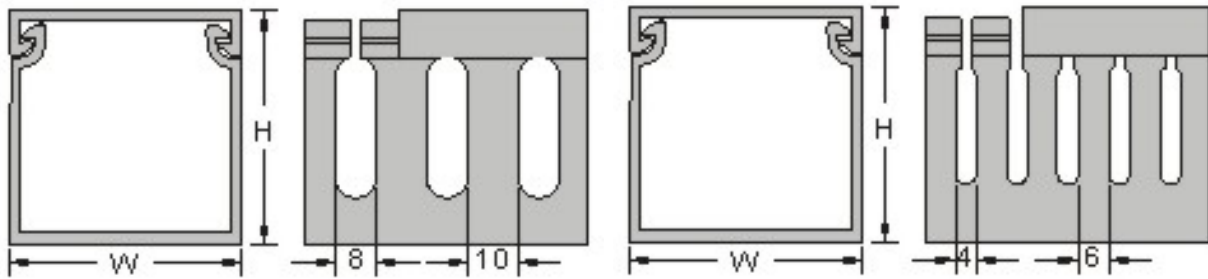

8MM SLOT

4MM SLOT

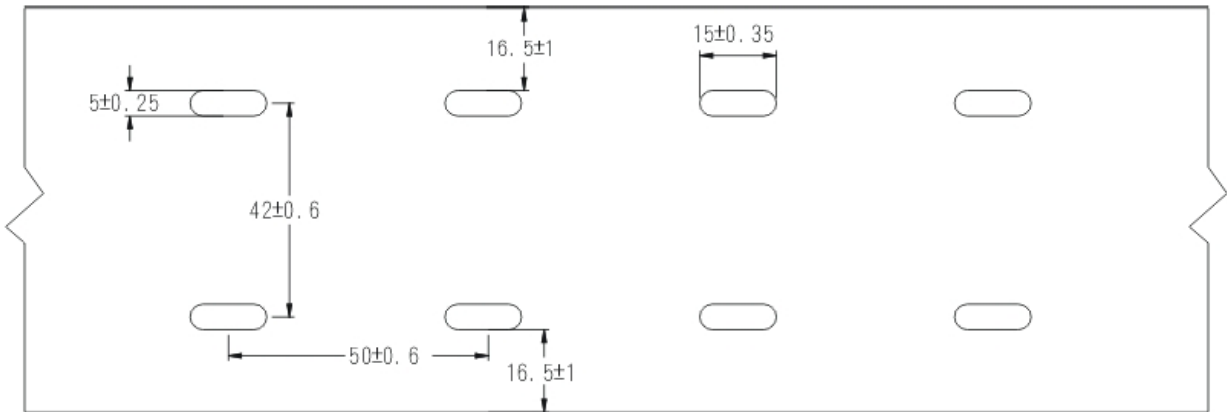

RS Article No	W(mm)	H(mm)	Slot	Length
758-9248	80	80	8mm	2M
758-9305	80	60		
758-9314	80	80	4mm	2M
758-9244	80	60		
879-3753	80	80	8mm	1M
879-3735	80	80	4mm	