


## High Current Switches

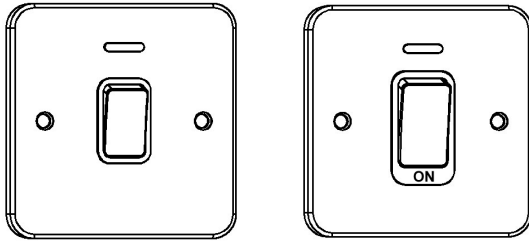

### Description

This stylish range is easy to install, with clear white terminal markings and the frontplates are supplied in protective bags.

### Features

- supplied with back box
- concave rockers
- only one size 4mm screw driver needed
- clear white terminal markings
- colour coded terminal
- terminals have large tapered lead-ins
- captive and backed out terminals
- discreet neon
- 2 earth terminals
- front plate comes in protective bag
- 25 year guarantee

### Range

1g 20A DP	M1213
1g 20A DP, neon	M1214
1g 20A DP, neon & flex outlet	M1214FL
1g 45A DP, neon	M1300P

### Technical Specification

voltage rating	250Vac
current rating	see range table
contact gap	3mm
size 1g	78mm x 78mm
depth	46mm

### Back Boxes

	knockouts	
	sides	back
1g	5	1

- all knockouts are 20mm dia.

no user serviceable parts

### Standards

- BS EN 60669-1:2000

### Terminal Capacity

L & N	2.5mm <sup>2</sup>	4mm <sup>2</sup>	6mm <sup>2</sup>	10mm <sup>2</sup>
20A	4	2	1	1
45A	-	3	2	1

## DETA

Kingsway House, Laporte Way  
Luton, Beds LU4 8RJ UK  
Tel. +44 1582 544 500 Fax: +44 1582 544 501  
Technical Helpline +44 1582 544 548