


# push-in Y-connector CRQSY-6

Part number: 130657

FESTO

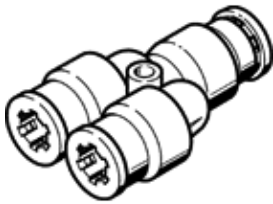

## Data sheet

Feature	Value
Size	Standard
Nominal size	3.3 mm
Assembly position	Any
Design	Y-shape
Container size	1
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 10 bar
Maritime classification	see certificate
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water as per manufacturer's declaration at <a href="http://www.festo.com">www.festo.com</a>
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	4 - Very high corrosion stress
Food-safe	See Supplementary material information
Ambient temperature	-15 ... 120 °C
Product weight	24 g
Number of outputs	2
Number of supply lines	1
Usable wires	PFAN
Pneumatic connection, port 1	For tubing outside diameter 6 mm
Pneumatic connection, port 2	For tubing outside diameter 6 mm
Materials note	Conforms to RoHS
Material housing	High alloy steel, non-corrosive
Material release ring	High alloy steel, non-corrosive
Material of tubing seal	FPM
Material of tube retaining claw	High alloy steel, non-corrosive