

Datasheet

RF video cable w/BNC plugs,4x75ohm 1.80m

RS Stock 172-2981




Specifications

- Inner Conductor: 7 x 12/100 copper (0.35mm)
- Insulation: PE (1.55mm)
- Screen: Copper (2.00mm)
- Jacket: PVC (2.50mm)
- Colours: Red – Green – Blue – Black
- Out Jacket: Ergonomic black PVC (7.20mm)

- Weight: 12.7 g/m
- Bend Radius: 15mm
- Operating temp: -40°C a + 85°C
- Nominal impedance: 75 ohms
- Velocity of propagation: 65.9 %
- Frequency range: DC- 4 GHz
- Dielectric strength rating: 1000 veff
- Operating voltage: 450 veff max

Dimensions: (mm)

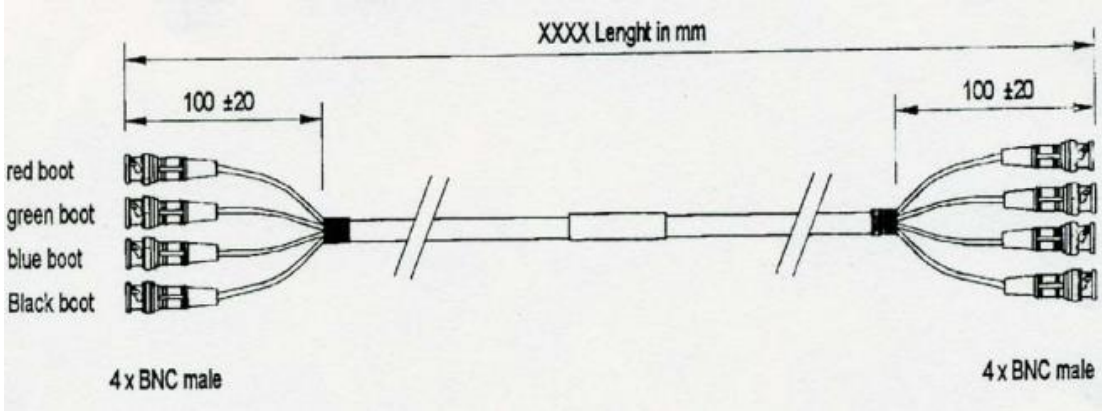

Frequency (MHz)	Attention (dB/m)	Power Rating (W)
50	0.20	100
100	0.30	80
300	0.45	45
1000	1.00	25