

Datasheet

USB A to USB B 2.0 Cable A-B

ENGLISH

RS Stock No.: 790-3931





Description

- Type: A-B
- Length: 1.8 m
- Colour: white

Technical Data - Overview

Product group	Cable
Conveyance good	No
Length	1.8 m
side 1 connector	Type A Male
side 2 connector	Type B Male
Left Connector Type	USB 2.0 Type A
Left Connector Gender	Male
Right Connector Type	USB 2.0 Type B
Right Connector Gender	Male
Colour (Cable)	white
Max. bandwidth	480Mbit/s
Area of application	External
Cable shielding	Screened
Hand locking screws	No

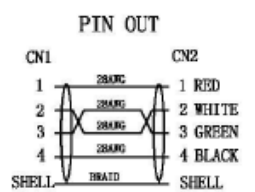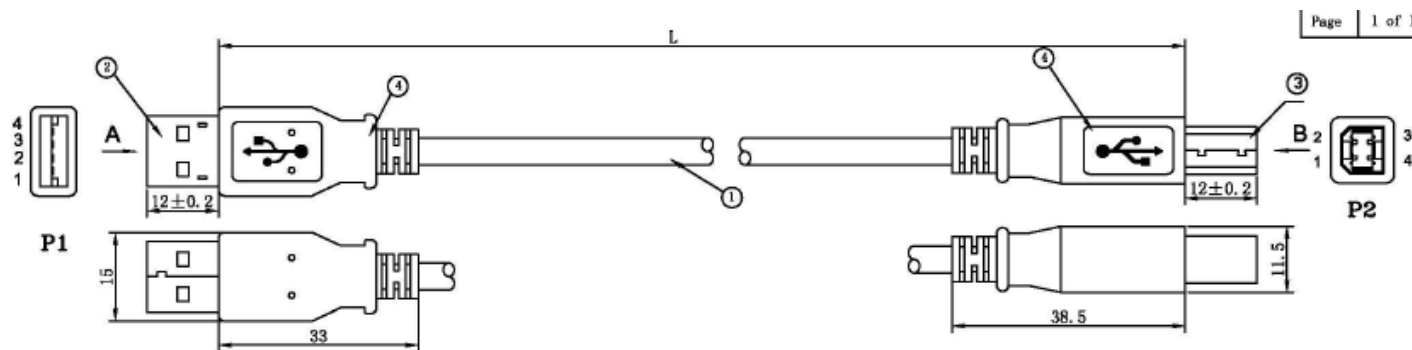

NOTE:

ITEM NO	LENGTH
11. 99. 8809	800mm
11. 99. 8819	1800mm
11. 99. 8831	3000mm
11. 99. 8841	4500mm

- NOTE:**
1. Electrical test:
 - (1). 100% open short & miss wire test;
 - (2). Insulation resistance: DC 300V 10M Ω;
 - (3). Contactor resistance: 3Ω Max;
 - (4). Dielectric strength: 100V AC/Minute, 1mA.
 2. RoHS & REACH compliant
 3. PRINTING: USB 2.0 CABLE, 28AWG×1P+28AWG×2C
 4. Packing: 1PCS/PE BAG + LABEL 100PCS/CARTON

MATERIAL LIST:

④	OUTER MOLD	Shore 88A PVC (UL94V-2) Color: White	2
③	USB B TYPE	USB B /M Type, The Pin Gold Plating 30U", the shell for Nickel Plating	1
②	USB A TYPE	USB A /M Type, The Pin Gold Plating 30U", the shell for Nickel Plating	1
①	CABLE	USB 2.0 28AWG (7/0. 12BC*1P)+28AWG (7/0. 12BC*2C)+AB B=0. 12/3*16 AL-MG JACKET: PVC/WHITE 00: 4. 0mm, Braid Coverage: 48%	1