

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

5055780871

Status:


Active

Overview:

Micro-Lock Plus Wire-to-Board Connector System

Description:

Micro-Lock PLUS Right-Angle Header, 2.00mm Pitch, Single Row, Matte Tin Plating, 8 Circuits, Black

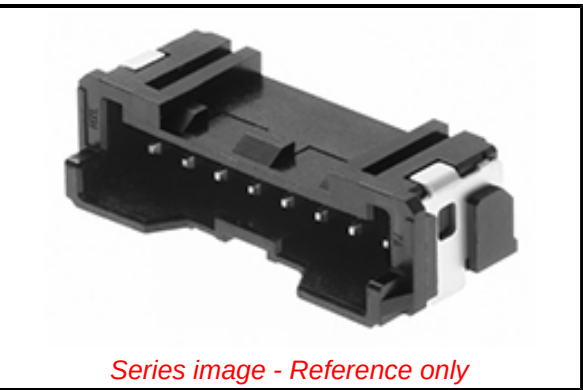

Documents:

3D Model

Drawing (PDF)

Product Specification 5055700001-PS-000 (PDF)

Application Specification 5055700001-A02 (PDF)

Application Specification 5055700001-A03 (PDF)

Packaging Specification 5055789200-200 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	PCB Headers
Series	505578
Application	Signal, Wire-to-Board
Overview	Micro-Lock Plus Wire-to-Board Connector System
Product Name	Micro-Lock PLUS
UPC	889056580021
Physical	
Breakaway	No
Circuits (Loaded)	8
Circuits (maximum)	8
Color - Resin	Black
Durability (mating cycles max)	30
First Mate / Last Break	No
Glow-Wire Capable	No
Guide to Mating Part	Yes
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Metal	Brass
Material - Plating Mating	Matte Tin
Material - Plating Termination	Matte Tin
Material - Resin	Polyamide
Net Weight	893.040/mg
Number of Rows	1
Orientation	Right Angle
PCB Locator	No
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	2.00mm
Pitch - Termination Interface	2.00mm
Plating min - Mating	1.000µm
Plating min - Termination	1.000µm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Surface Mount
Electrical	
Current - Maximum per Contact	3.0A
Voltage - Maximum	250V AC (RMS)/DC
Material Info	
Reference - Drawing Numbers	

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per -ED/88/2018 (15 January 2019)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

505578 Series

Mates With

Micro-Lock PLUS Receptacle Housing 505570

Application Specification	5055700001-A02, 5055700001-A03
Packaging Specification	5055789200-200
Product Specification	5055700001-PS-000
Sales Drawing	5055780001-000, 5055780001-001

This document was generated on 05/16/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION