

EKP 30-G



Sample image

Order symbol : EKP 30-G

Product nr : 3730143




Description : Cover, PC

Remarks : Grey

EAN : 6418074000361

El. number :

- Finland : 3420171
- Denmark : 8212007181
- Sweden : 2537868

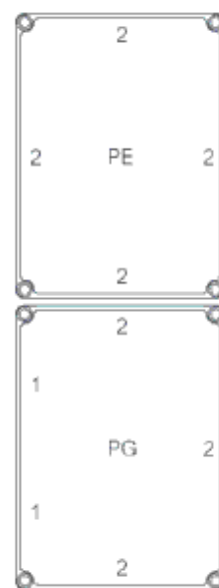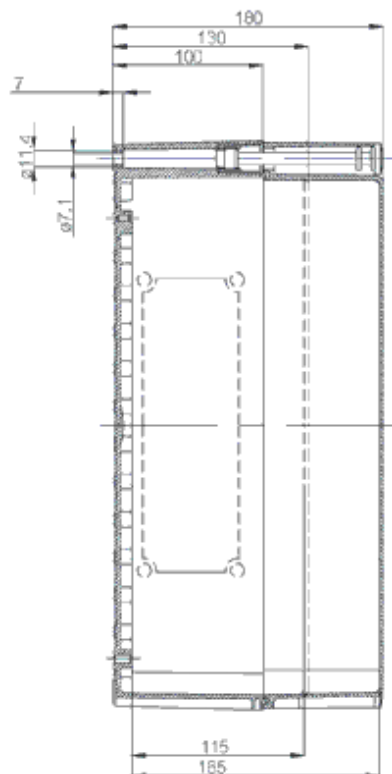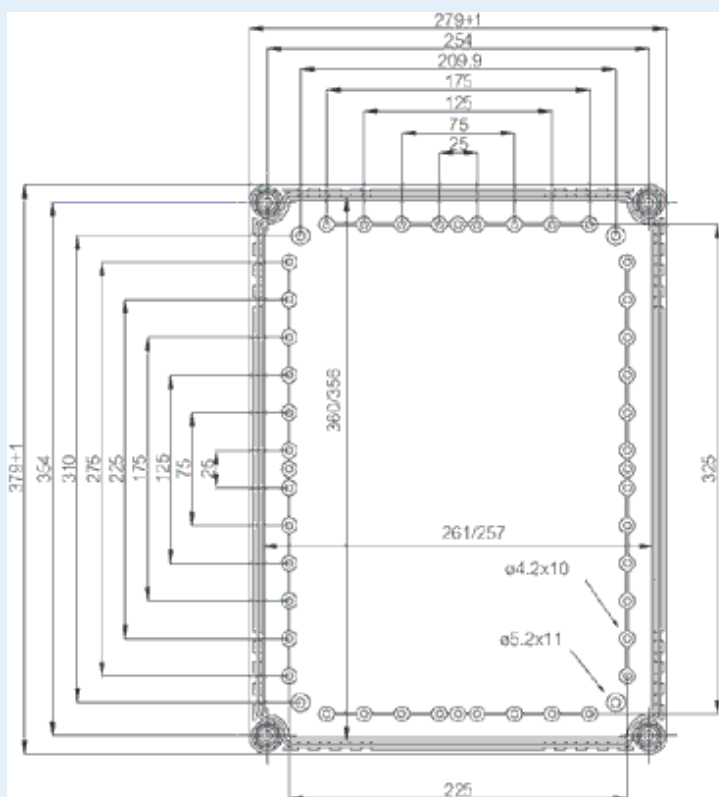

Dimensions :

	Height	Width	Depth
mm :	380	280	30
inch :	14.96	11.02	1.18

Accessories :

EKV 32	DIN-35 Mounting rail, for enclosures: (335 x 35 x 7)
EKV 22	DIN-35 Mounting rail, for enclosures: (235 x 35 x 7)
EKPZR	Extension frame, for enclosures:

Materials :	
Material :	Polycarbonate
Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

Temperatures :	
Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

	(380 x 280 x 50)
EKPVT	Mounting plate, for enclosures: (338 x 238 x 1.5)
MPI EKP 3828	Multiperforated plastic mounting plate (338 x 238 x 4)
DRS EKP 2838 2x19M	DIN rail set (364 x 264 x 90)
DRS EKP 3828 3x14M	DIN rail set (364 x 264 x 90)

Ratings :	
electrical_insulation :	Totally insulated
UV resistance :	UL 746C
Flammability Rating :	UL 94 V0
Glow Wire Test (IEC 695-2-1) °C :	960C

Certificates :	
SGSFIMKO_EK	