




**LED Ecobasic Stick T37 E14 7W (48W) 600lm 830 100V-260V**

Article number: 146776

BAI LED Ecobasic Stick T37 E14 100V-260V/AC 7W (48W) 600lm 3000K Opal 200° 37x115mm 120V 130V 230V 240V 50/60Hz LED Lamp

The wide voltage range makes this LED lamp very versatile.

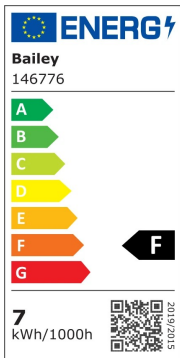

**General ETIM properties**

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED Ecobasic Stick T37 E14 7W (48W) 600lm 830 100V-260V
Brand	Bailey
Productseries	Ecobasic LED stick
Producttype	Compact E14

## ETIM specifications

Socket	E14
Luminous flux [lm]	600 - 600
Nominal voltage [V]	100 - 260
Lamp power [W]	7 - 7
Colour temperature [K]	3000 - 3000
Diameter [mm]	37
Length [mm]	115
Dimmable	No
Lamp shape	Tube, single-ended
Beam angle [°]	200 - 200
Colour	White
Type of glass/cover	Opal
Lamp designation	Other
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	No
Rated luminous flux according to IEC 62612 [lm]	600
Power factor	0.8
Lamp efficacy [lm/W]	85
Nominal current [mA]	40 - 40
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	White
Average nominal lifetime [h]	20000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	10000
Weighted energy consumption in 1000 hours [kWh]	7
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG0
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	No
Dimming phase cut-on (leading edge)	No
Dimming Touch and Dim	No
Dimming Zigbee	No

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	F
With twilight switch	No
Material of light bulb	Plastic

## Predecessor



143486

LED T38X108 E14 95-265V 5W  
(50W) 640lm 830 Opal