




Notes: (Unless Otherwise Specified)


1. Waterproof Rate: IP68.
2. Cable Diameter: 5.0 to 6.0 mm
3. Recommend Gland Nut Torque: 9.0 to 10.0 Kgf-cm.

RoHS Compliant

REV	ECN#	DESCRIPTION OF REVISION	DRAW BY DATE	CHECK BY DATE	APPROVE BY DATE
A0		Mass Production	Joyce 04/24/12	Lucas 04/24/12	Ray 04/24/12

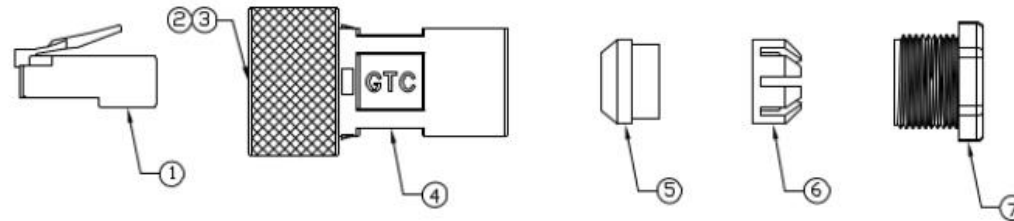

7	Gland Nut	Thermoplastic Color: Black	1
6	Cage	Thermoplastic Color: White	1
5	Gland	Silicone Color: Green	1
4	Housing	Thermoplastic Color: Black	1
3	Screw Nut	Copper Alloy Finish: Ni Plated	1
2	Rubber Pad	Silicone Color: Black	1
1	RJ45 Plug	Housing: Thermoplastic, Color: Green Contacts: Copper Alloy, Finish: Ni Plated Shell: Cold Roll Steel, Finish: Ni Plated	1
Item	Part Name	Material / Finish	Qty

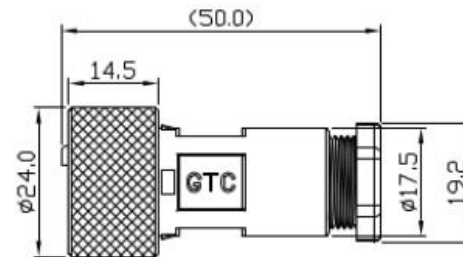

Mating Parts:
111-6739
111-6740

TITLE										
RJ45 Metal C3 Shielded E1 Field Installable Cable End Plug Screw										
THIRD ANGLE PROJECTION										
SIZE	SCALE	DRAW / DATE	CHECK / DATE	APPROVE / DATE	TOLERANCES		UNIT	SHEET		
B	1:1	Joyce 04/24/12	Lucas 04/24/12	Ray 04/24/12	XX X.XX	± 0.5 ± 0.2	X.XXX ANGLES	± 0.05 ± 1°	mm	1/1

RS Stock No
111-6742