

Features

- Full Copper
- UTP
- PVC
- Injection Moulded
- 26AWG
- ANSI/TIA-568-B.2 3P
- Gold Plated Contacts
- ISO/IEC 11801
- CE
- UKCA
- ROHS
- REACH

RS PRO Yellow CAT 5E UTP PVC Injection Moulded Patch Lead 100% Copper

RS Stock No. 0834508



RS Professionally Approved Products bring to you, professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

The RS Pro range of CAT5e networking cables run at speeds up to 10/100. The internal conductors are made from 26awg 100% Full copper, have a PVC jacket and the outer diameter is 4.6mm. The connectors are RJ45 (8P8C) and the pins are gold plated to help prevent corrosion.

The wiring uses the TIA/EIA-568B wiring which is standard for most networking uses. The cables are UL certified to CM(UL) C(UL) CMH. We have a wide variety of colours and lengths.

General Specifications

Connector A	RJ45 Male
Connector B	RJ45 Male
Length	15cm up to 20mtr
Outer Sheath Material	PVC
Sheath Colour	Yellow
Shielding	UTP


Approvals

Declarations	CE UKCA REACH ROHS ANS/TIA-568-B.2 3P ISO/IEC 11801
Standards Met	CE UKCA REACH ROHS ANS/TIA-568-B.2 3P ISO/IEC 11801

Similar Products

Stock No.	Length	Spec	Colour
0834508	15cm	CAT 5E UTP PVC	Yellow
286-3555	25cm	CAT 5E UTP PVC	Yellow
286-3562	0.5mtr	CAT 5E UTP PVC	Yellow
286-3586	1mtr	CAT 5E UTP PVC	Yellow
286-3576	1.5mtr	CAT 5E UTP PVC	Yellow
286-3599	2mtr	CAT 5E UTP PVC	Yellow
286-3611	3mtr	CAT 5E UTP PVC	Yellow
286-3620	4mtr	CAT 5E UTP PVC	Yellow
286-3632	5mtr	CAT 5E UTP PVC	Yellow
286-3640	6mtr	CAT 5E UTP PVC	Yellow
286-3650	7mtr	CAT 5E UTP PVC	Yellow
286-3663	10mtr	CAT 5E UTP PVC	Yellow
286-3671	15mtr	CAT 5E UTP PVC	Yellow
286-3680	20mtr	CAT 5E UTP PVC	Yellow

Also available in our RS PRO range of CAT 5E cables are the colour options:
Grey, Brown, Blue, Black, Orange, Green, Pink, Violet, White and Red

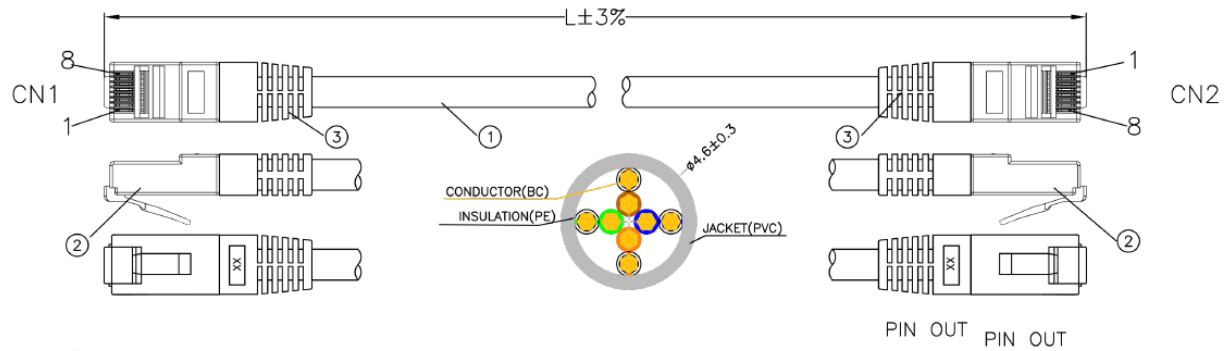

MATERIAL LIST:

NO.	PARTS NAME	SPECIFICATION DESCRIPTION
①	CABLE	U/UTP [26AWG(BC 7/0.145±0.005)*1PR]*4+PVC OD:4.6±0.3mm COLOR:Assorted upon request
②	RJ45 CONNECTOR	RJ45,8P8C,TWOFORK GOLD PLATED CONTACTS
③	MOLDING PVC	MOLDING PVC 45P COLOR:Assorted upon request

Marking: CM (UL) C(UL) 4P 26AWG U/UTP CAT5E STRANDED PATCH ISO/IEC 11801 AND ANSI/TIA-568-C.2

PIN OUT		PIN OUT	
CN1	WIRE COLOR	CN2	
1	ORANGE/WHITE	1	
2	ORANGE	2	
3	GREEN/WHITE	3	
6	GREEN	6	
4	BLUE	4	
5	BLUE/WHITE	5	
7	BROWN/WHITE	7	
8	BROWN	8	

ELECTRONIC TEST:

A.OPEN/SHORT/INTERMITTENCE: 100%.

REMARK NO	CHA NO	SIGNATURE	DATE						
DRAWN BY	Renzhi			SIGN			W.T	SCALE	U/UTP CAT 5E 26AWG PVC