


Blue Elastic Rubber Trolley Wheel 100mm, ball bearings, 150kg

Elastic Rubber-tyred wheel

PRODUCT

Article number **571-411-100B12**

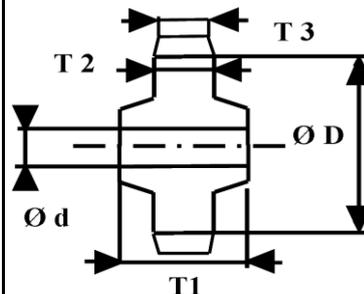

Product Details

Wheel Rim : very thick black polyamide.
 Tyre : solid, blue bonded elastic rubber tyre, non marking.
 Hub : symmetrical, two ball bearings.

Specifications

Wheel Diameter - ØD ± 1%	100mm
Hub Type	two ball bearings
Hub Length T1	45 mm ±1
Width of Tread T2	36 mm ±1
Width of Tread-on floor T3	36 mm ±1
Axle Hole Ø d	Ø 12 mm
Hardness of tread A ±4	A 70 Shore
Load capacity	150 Kg
Temperature	-20 / +60 °C
Weight	0,34 kg

TECHNICAL DATA

Applications :

Sensitive materials handling on uneven surfaces.
 Resilient with a low starting effort.
 Does not leave scratches or other marks on surfaces.
 Reduce shock and vibration.
 Quiet in use and high wear resistance.
 Suitable for industrial floors and also all interior floors.