

## Features

- 10kvar shunt reactor drive capacity
- Separate Thermal inputs
- Driveability from %0 to %100
- Intervention without delay
- System with the test button
- Thermal and status led
- Separate drive notification Led for T1,T2,T3
- Infinity contac life

## RS PRO Power Factor Correction Capacitors

RS Stock No.: 0434514



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

## Product Description

- *The inductive load drives can be used with the new generation SVC enabled RS PRO power factor relays. It designed to drive 3 single-phase shunt reactors.*
- *Prevent capacitive penalty*
- *Compensate capacitive loads powers*
- *It protect the client electrical system.*
- *It prevents electrical network fatigue.*

## General Specifications

Model Number (p)	RS PRO
Product type	Inductive load driver, thyristor module
Operating temperature	-20, +55
Storage temperature	-30, +80
Syrge protection	YES
Mounting type	Mounting on the vertical or terminal rail in the cabinet
Connection type	Terminal

## Mechanical Specifications

Width	123mm
Length	130,3 mm
Height	134,7 mm
Weight	<2200 gr

## Electrical Specifications

Operating voltage	85-260V AC
Safety Category voltage	CATII

Cable diameter	2,5mm
----------------	-------


## Protection Category

IP Rating	00
-----------	----

## Approvals

Compliance/Certifications	CE-UKCA
Hazardous Area Certification	ROHS-3

## Wiring Diagram

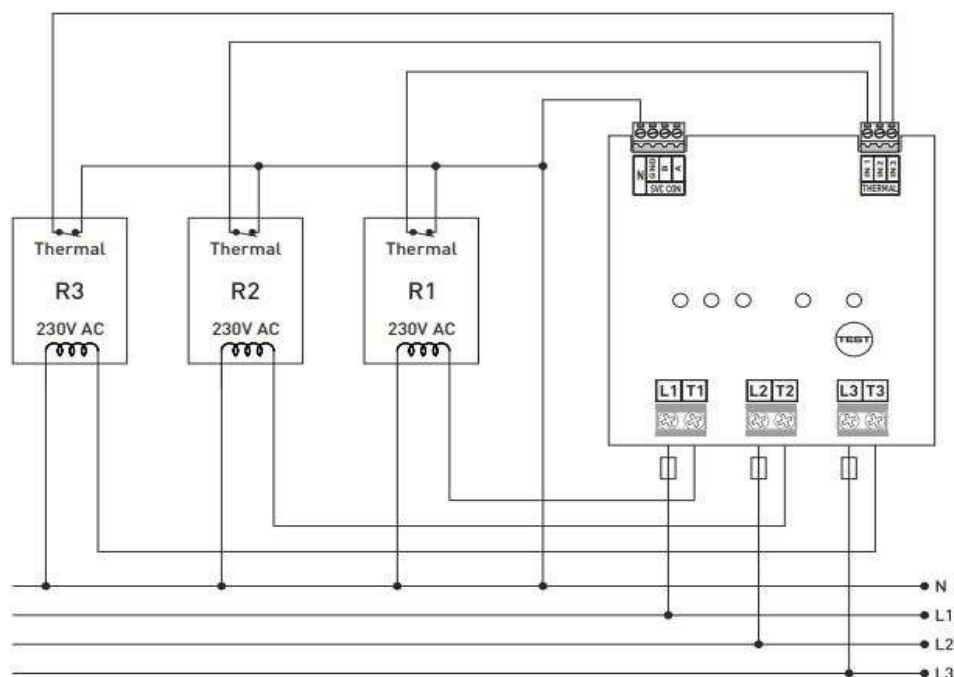

### Similar Products

Stock No.	Product Name	Attribute 1	Attribute 2	Attribute 3
0434503	Power factor correction capacitor	5 KVAR shunt reactor capacity driver	Driveability from %0 to %100	Intervention without delay