

## 440 - METRIC COMBINATION WRENCHES | 440.5H




### Norm :

**NF ISO 691, NF ISO 7738, NF ISO 3318, NF ISO 1711-1, E74-306, ISO 691, ISO 7738, ISO 3318, ISO 1711-1, DIN ISO 691, DIN 1711-1, DIN 3113, ASME B107.100**

### Description

- Standard wrench for all current applications.
- High mechanical strength combined with compact size meeting aeronautical standards.
- Ring head:
  - Ring open end (size E) designed for better access to series or embedded screws.
  - OGV® profile with 12-point ring for powerful tightening while protecting the nut. H suffix = 6-point ring.
  - Ring head angled at 15°.
- Open end head:
  - Open end angled at 15°.
  - Open end head-handle geometry optimised for increased access.
- Metric sizes: 4 to 41 mm.
- Presentation: satin chrome finish.

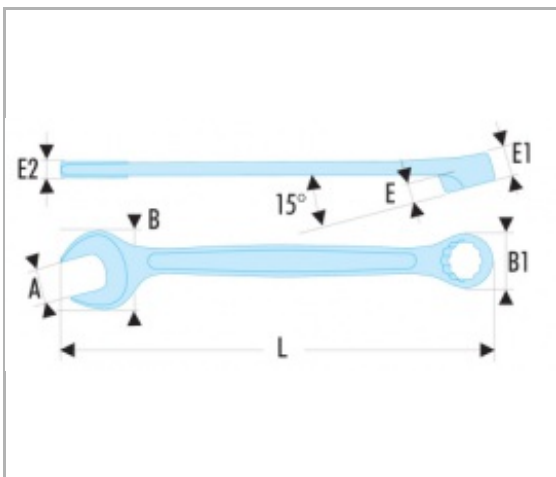

### Information

A [mm]	5
B [mm]	13,3
B1 [mm]	9,2
C1 [mm]	6,0
E [mm]	3,1
E1 [mm]	6,0
E2 [mm]	3,6
L [mm]	115
[g]	16

