


T-ST-CONNECTOR FEMALE

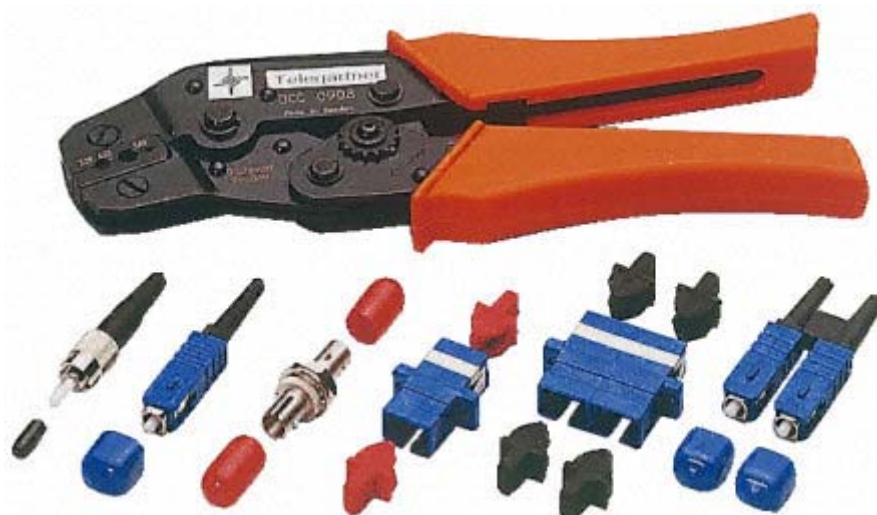

Specifications

Colour	Blue
Connector Type	T-ST
Fibre Size	125µm
Insertion Loss	0.4dB
Single/Multimode	Multimode, Single Mode

T-ST and T-SC Plug Connectors

Zirconium ceramic ferrules and sleeves

On-site assembly with standard commercial tools

Hexagonal crimp width: 4.52 x 10 mm

Pre-fabricated convex front face ensures short polishing times and excellent optical properties

Coupling suitable for multimode and single mode

Insertion loss at couplings: 0.2 dB

Insertion loss at connectors: 0.4 dB

Colour of SC connector/ coupling housing: blue

SC couplings with plastic housing including self-cutting screws (snap or click-in mounting)

ST couplings with metal housing

Cable connection Ø: 2.6 → 3 mm