



General technical details:

Product designation		cable-operated switch
Number of indicator lights		0
Type of unlocking device		rotate-to-unlatch mechanism
Rope length / maximum	m	75
Item designation / according to DIN 40719 extendable after IEC 204-2 / according to IEC 750		S
Item designation / according to DIN EN 61346-2		S
Width	mm	67
Height	mm	209
Depth	mm	53

Enclosure:

Type of fixing/fixation		screw fixing
Material / of the housing		metal
Color / of the top part of housing		grey

Contact:

Number of NC contacts / for auxiliary contact		3
Number of NO contacts / for auxiliary contact		1
Switching function / arresting lock		Yes

Certificates/approvals:

Acceptability for application / NETWORK OPERATING
EMERGENCY OFF switch

Yes

Ambient conditions:

Protection class IP

IP65

Ambient temperature

- during the operating phase

°C

70 ... -25

Further information:

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/industrial-controls/catalogs>

Global Industry Mall (Online ordering system)



<http://www.siemens.com/industrial-controls/mall>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<http://support.automation.siemens.com/WWW/view/en/3SE7141-1EG10/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)

http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3SE7141-1EG10

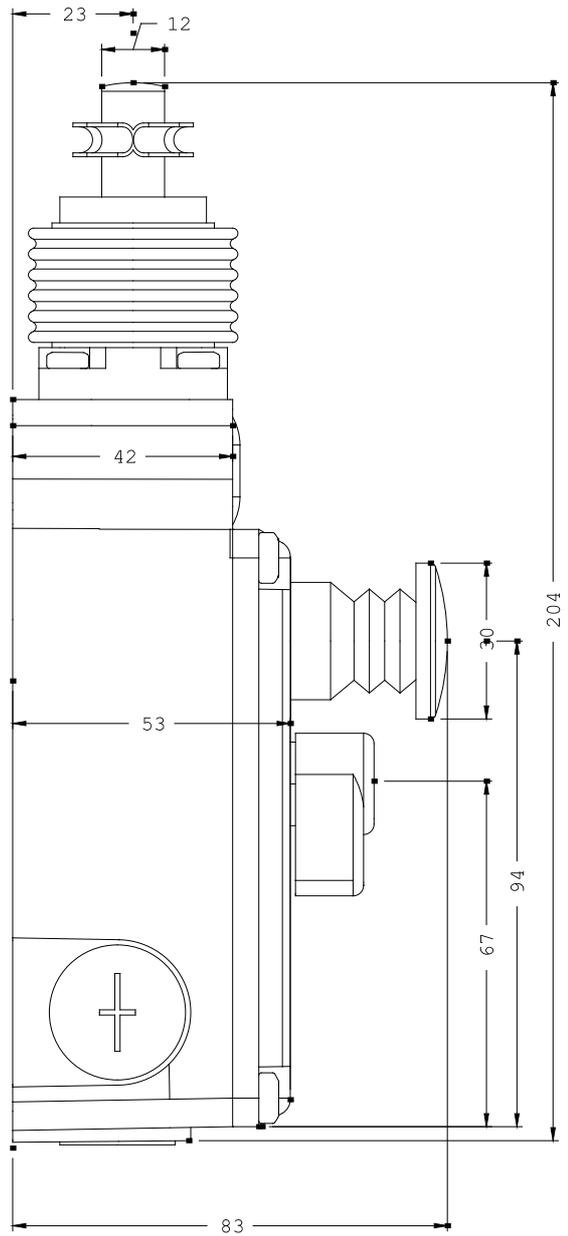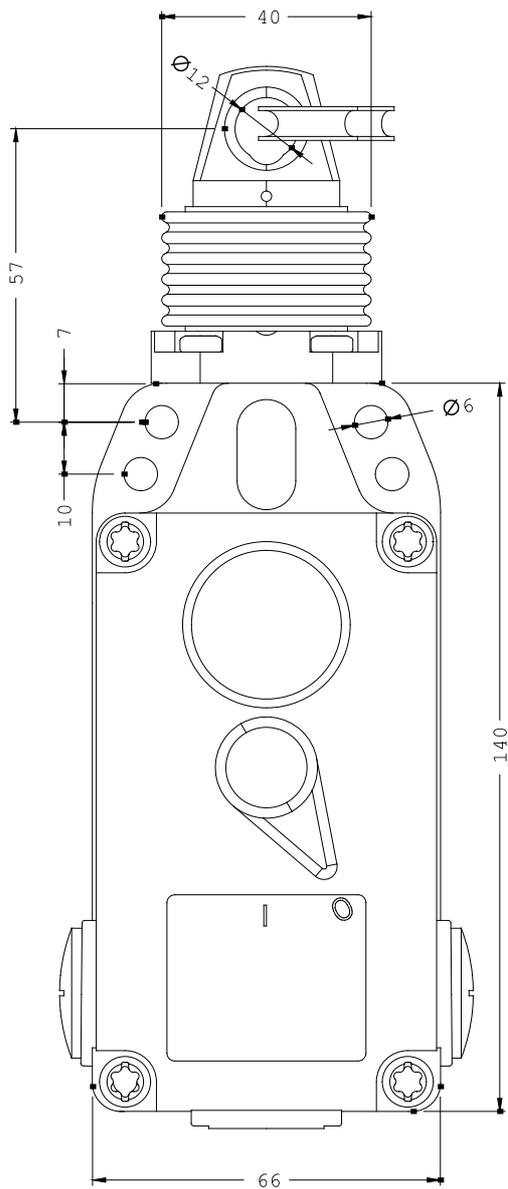

last change:

Jun 14, 2010