



SIVACON, Roof, Closed, IP40, W: 600 mm, T: 800 mm, zinc-plated

Model	
product brand name	SIVACON
product designation	top plate
design of the product	Closed
design of the surface	zinc plated
design of the product EMC version	No
Protection class	
protection class IP	IP40
Suitability	
suitability for use for outside use	No
Product details	
product component	
<ul style="list-style-type: none"> <li>• cable entry</li> <li>• ventilation</li> </ul>	<p>No</p> <p>No</p>
Mechanical Design	
width	600 mm
depth	800 mm
net weight	6.1 kg
material	steel

Approvals Certificates		
General Product Approval	Test Certificates	other



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

other	Environment
-------	-------------

[Miscellaneous](#)



[Environmental Confirmations](#)

### Further information

Information on the packaging  
<https://support.industry.siemens.com/cs/ww/en/view/109813875>  
 Information- and Downloadcenter (Catalogs, Brochures,...)  
<http://www.siemens.com/lowvoltage/catalogs>  
 Industry Mall (Online ordering system)  
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mifb=8MF1068-2UD10-0A>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<http://support.industry.siemens.com/cs/ww/en/ps/8MF1068-2UD10-0A>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mfb=8MF1068-2UD10-0A](http://www.automation.siemens.com/bilddb/cax_en.aspx?mfb=8MF1068-2UD10-0A)

CAx-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

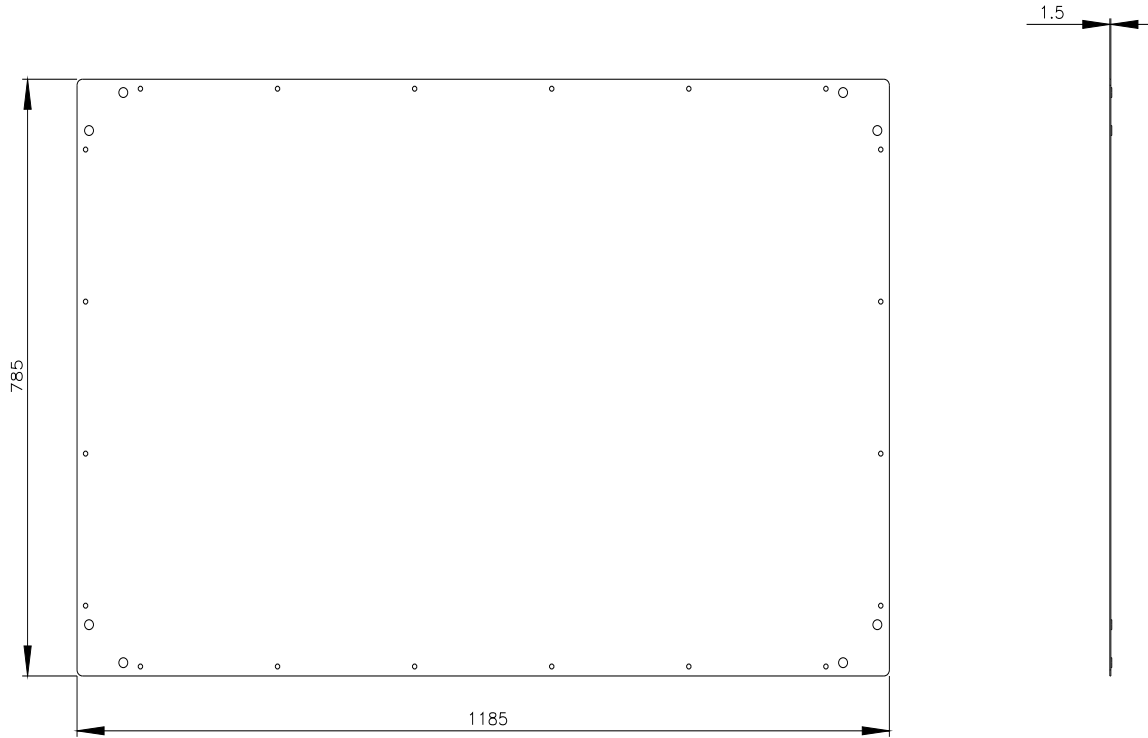

last modified:

7/24/2023 

