


FEATURES

- **Enclosed design:** Provides protection and durability for the driver components
- **3 in 1 Dimming:** Allows for versatile dimming options, enhancing lighting control
- **3.12 A driver current:** Ensures sufficient power delivery for LED systems
- **220-240 V AC input voltage:** Compatible with standard AC power supplies
- **IP20 rating:** Suitable for indoor use, protecting against dust ingress
- **Constant Voltage operation:** Maintains stable voltage output for consistent lighting performance
- **Single output:** Simplifies installation and reduces wiring complexity

RS PRO Enclosed LED Driver, 3.12 A 24 V

RS Stock No: 625-750

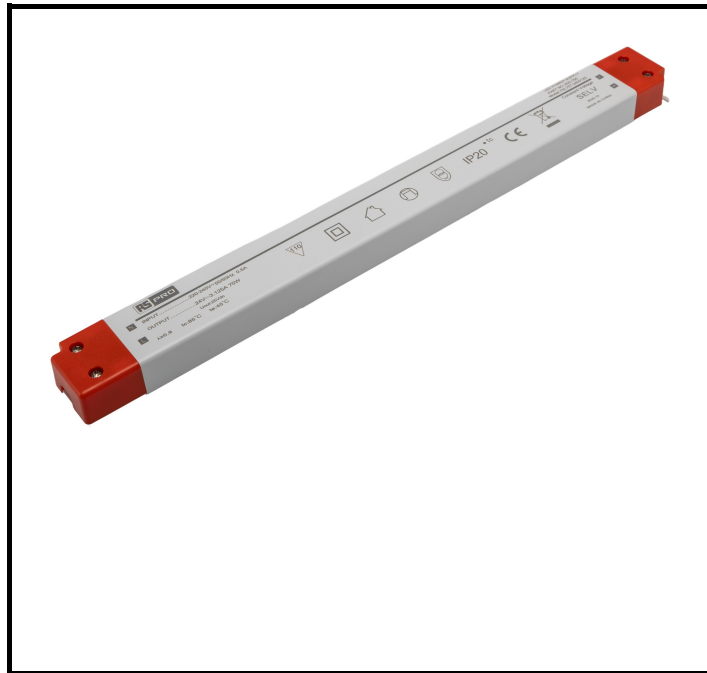

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

This RS PRO enclosed LED driver is designed to provide a reliable power supply for LED lighting systems. With a constant voltage output of 24 V and a maximum output power of 75 W, it ensures efficient operation for various lighting applications. The driver supports 3 in 1 dimming, offering flexibility in controlling light intensity.

General Specifications

Configuration	Enclosed
Dimming Operation	3 in 1 Dimming
Number of Outputs	1
Operating Modes	Constant Voltage
Primary Type	AC to DC
Product Type	LED Driver
Sub Type	Constant Voltage LED Driver

Electrical Specifications

Driver Current	3.12 A
Input Voltage	220-240 V ac
Input Voltage Type	AC
Maximum Output Power	75 W
Output Voltage	24 V

Protection Category

IP Rating	IP20
-----------	------

Approvals

Standards/Approvals	CE, EN55015, EN61000-3-2 Class C, EN61000-3-3, EN 61347-1, EN 61347-2-13, EN61347-2-12:2014+A1:2017, EN61347-1:2015+A1:2021, EN61547:2009, EN62493:2015, REACH, RoHS, TUV, UKCA
---------------------	---

