


Jack connectors



Jack plug acc. to JIS C 6560 JC35P2, 3.5 mm, 2 poles/mono, angular version, with solder terminals

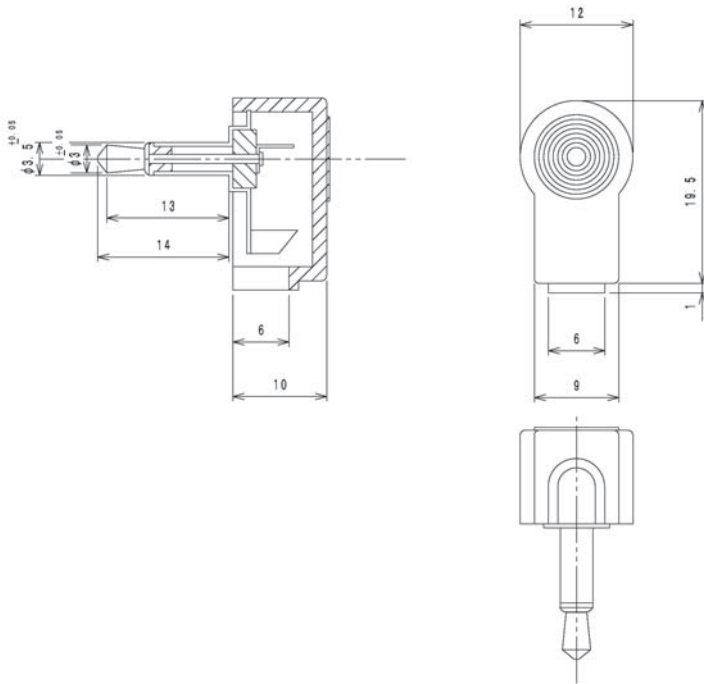

Environmental conditions

Temperature range -20 °C/+70 °C

Materials

Insulating body Ebonit
Contact CuZn/steel, nickel-plated
Housing PE

Connectable conductors for solder area

Cable diameter 4 mm

Electrical data (at T_{amb} 20 °C)

Rated current 1 A
Rated voltage 34 V AC/DC
Rated impulse voltage 500 V/60 s
Insulation resistance $\geq 100 \text{ M}\Omega$

Associated products

Counterparts

☞ 1502 03

☞ 1503 22

☞ 1522 02

☞ 1522 03

15

WKLS 2

Designation	Pole Number	PU (Pieces)	MDQ (Pieces)
WKLS 2	2	100	500

Packaging:

in bulk, in a cardboard box or a plastic bag