


## LaserRange-Master T4 Pro



Laser distance meter –  
with Bluetooth interface  
and angle function

Rev.1.116

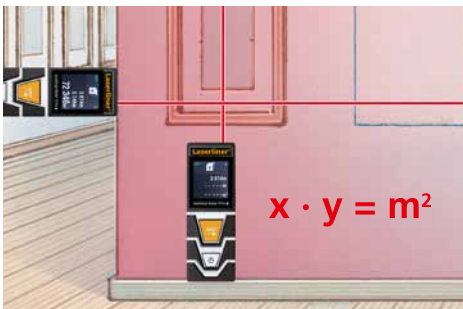

- Point-precise measuring with laser to determine lengths exactly
- The area and volume functions permit the acquisition of room sizes, for example to calculate material quantities
- Bluetooth interface for measurement data transfer
- 360° inclination sensor for determining the horizontal and vertical distance
- High measuring accuracy up to 40 m: ± 2 mm\*
- Inside measurement range: 0.2 m to 40 m
- 3 selectable measurement reference points: front, tripod and rear
- Continuous measuring function
- Illuminated 3-line colour LCD with touch function
- Stable, ergonomic housing


### TECHNICAL DATA

<b>ACCURACY</b> ± 2 mm (typical)*
<b>MEASUREMENT RANGE</b> max. 40 m
<b>MINIMAL RANGE</b> 0,2 m
<b>LASER</b> Class 2 < 1mW
<b>LASER WAVELENGTH</b> 650 nm
<b>OPERATING TEMPERATURE</b> -10°C ... 40°C
<b>STORAGE TEMPERATURE</b> -20°C ... 70°C
<b>UNIT</b> (selectable) m / ft / inch / ' _ ' "
<b>AUTOMATIC SWITCH-OFF</b> dynamic depending on measuring mode: Laser: 30 s - 5 min Device: 3 min - 8 min
<b>FUNCTIONS</b> distances, areas, volumes, continuous measurement, Pythagoras 1 + 2, angle function 1 + 2
<b>POWER SUPPLY</b> Batteries 2 x 1.5 V type AAA
<b>DIMENSIONS</b> (W x H x D) 100 x 23 x 35 mm
<b>WEIGHT</b> with batteries 82 g

\* See operating instructions for specific accuracies



**LaserRange-Master T4 Pro**  
inclusive softbag  
+ batteries (2 x 1.5 V type AAA)  
**Packaging dimension** (W x H x D)

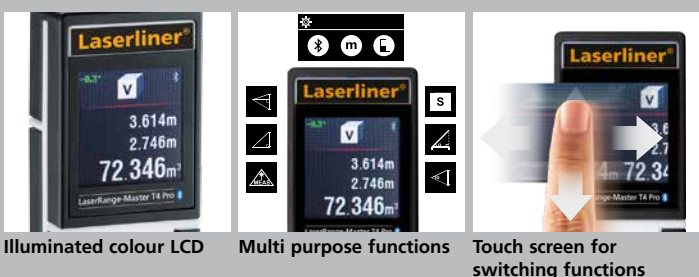

Illuminated colour LCD

Multi purpose functions

Touch screen for switching functions

ARTICLE	ARTICLE NO	EAN-CODE	PU
LaserRange-Master T4 Pro	080.850A	4 021563 698158	5

