

AS-Interface adapter element, black, with/without external auxiliary voltage, can be selected, standard AS-i, for 4 signaling elements, 24 V DC, Diameter 70 mm



Figure similar

General technical data	
Product brand name	SIRIUS
Product designation	AS-Interface module
Type of voltage of the operating voltage	DC
Operating voltage	
• at DC rated value	18.5 ... 31.6 V
• 1 at DC rated value	24 V
Consumed current maximum	210 mA
Color	black
Mounting type	Bayonet
Reference code	
• acc. to DIN EN 61346-2	B
• acc. to DIN EN 81346-2	B
Mechanical data	
Outer diameter of the signal column element	70 mm
Ambient conditions	

Ambient temperature during operation	-20 ... +50 °C
Protection class IP	IP65
Design of the interface AS-interface protocol	Yes
Height	65.5 mm
Width	70 mm

Certificates/approvals

General Product Approval	EMC	Declaration of Conformity	other
--------------------------	-----	---------------------------	-------



[Confirmation](#)

Further information

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/industrial-controls/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8WD4428-0BE>

Cax online generator



<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=8WD4428-0BE>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8WD4428-0BE>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=8WD4428-0BE&lang=en

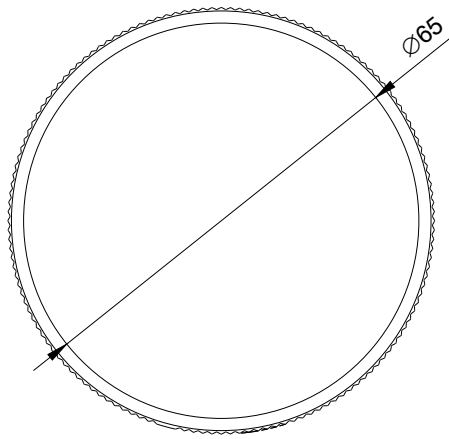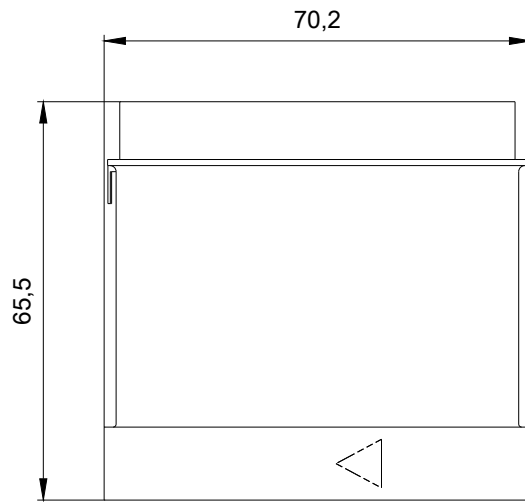

last modified:

W9.4444;
W9.375; 8WD4428-0Bx_ALL
11/13/2018