



## Technical data

### NATV30LL/3AS

Roller follower with inner ring

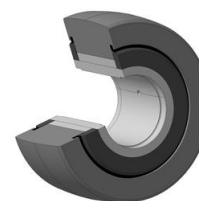

#### VISUAL (S)

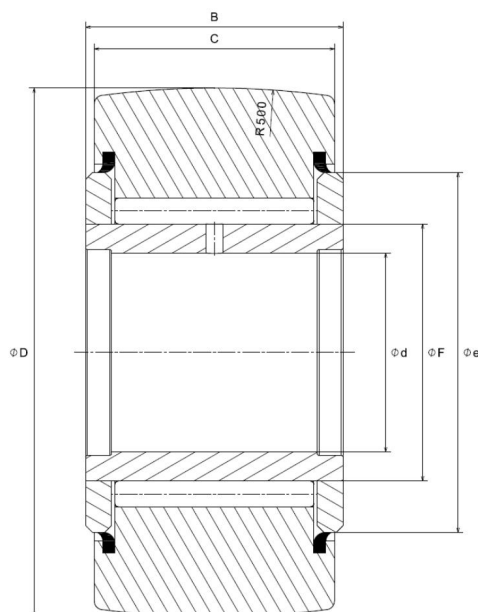

#### PRODUCT DEFINITION

|                                               |        |
|-----------------------------------------------|--------|
| Brand                                         | NTN    |
| d - Internal diameter                         | 30 mm  |
| D - External diameter                         | 62 mm  |
| C - Width of bearing, drawn cup or outer ring | 28 mm  |
| F - Under roller diameter                     | 38 mm  |
| B - Bearing/Inner ring width                  | 29 mm  |
| e - Inlet diameter of roller or washer        | 51 mm  |
| R - Track roller radius                       | 500 mm |
| Bearing with/without cage                     | Sans   |



#### NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00  
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072  
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

## PRODUCT DEFINITION

|                               |          |
|-------------------------------|----------|
| <b>Radial clearance class</b> | CN       |
| <b>Precision class</b>        | P0       |
| <b>Mass</b>                   | 0,481 kg |

## PRODUCT PERFORMANCE

|                                                 |             |
|-------------------------------------------------|-------------|
| <b>Cr - Dynamic load rating</b>                 | 47,5 kN     |
| <b>C0r - Static load rating</b>                 | 115 kN      |
| <b>Track load capacity spherical outer ring</b> | 6,95 kN     |
| <b>N lim - Grease lubrication limit speed</b>   | 2600 tr/min |
| <b>Tmin - Min operating temperature</b>         | -20 °C      |
| <b>Tmax - Max operating temperature</b>         | 100 °C      |

## ESHOPDONOTDISPLAY

|                                 |                                    |
|---------------------------------|------------------------------------|
| <b>Tracepart</b>                | Oui/Yes                            |
| <b>Reference</b>                | NATV30LL/3AS                       |
| <b>Image</b>                    | NRBNATV_LL_1.jpg, NRBNATV_LL_3.jpg |
| <b>Rolling element material</b> | Acier 100Cr6                       |

