


EASYRAK

Open Frame Rack

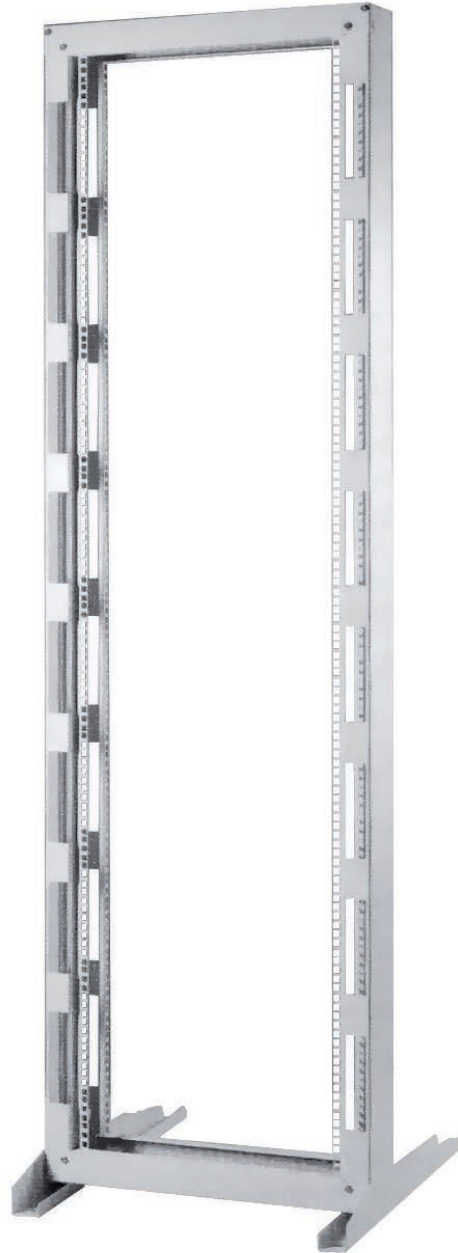

EASYRAK

Overview

Material specification

- **Frame:** Steel 1.5 mm
- **Wall brackets:** Steel 1.5 mm
- **Floor brackets:** Steel 3.0 mm
- **Top cover:** Steel 1.5 mm
- **EASYRAK load capacity:** 150 Kg

Standards

- IEC 60297:** Dimensions of mechanical structures of the 482.6 mm (19") series
- DIN 41494:** Basic specification for the 19" construction systems
- EN 60950:** European safety standard for information technology equipment
- VDE 0100:** Installation and Set up of current systems and earthing

Colour specification

Standard


RAL 7035 
Internal and external frame

Dimensions

Open Frame Rack

Depth: 300 - 450 mm

Width: 600 mm

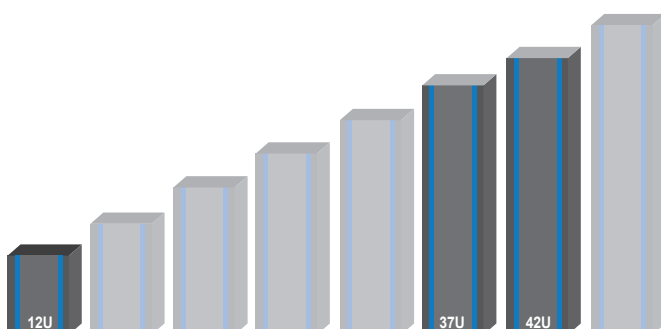

Introduction to EASYRAK



EASYRAK is an open frame rack designed for the mounting of 19" equipment, suitable for floor standing or wall mounted installation. Strong but lightweight, it can be combined with double castor wheels, covers, trays, shelves. Multiple EASYRAK may be joined together through the baying kit for multiple configurations.

Key Features:


- 360° accessibility
- Suitable for integrated cables management
- Flat pack supplied
- Suitable for floor fixing or for double castor wheels
- Static load up to 150Kg
- 600 x 450 mm footprint
- Several accessory options available
- RAL7035, other colors on request

Ordering information

Height	Finish	Order code
12U	RAL7035	VT052-255052
37U	RAL7035	VT052-255051
42U	RAL7035	VT052-255050

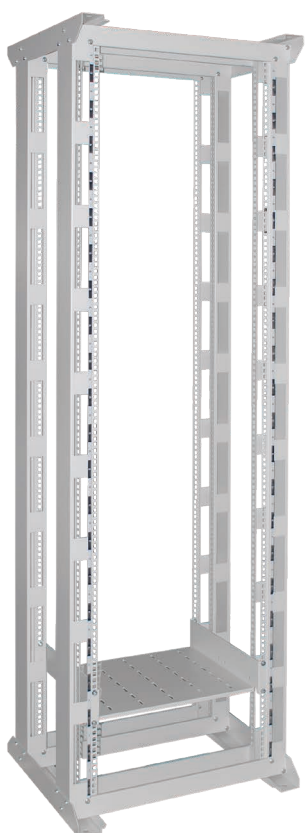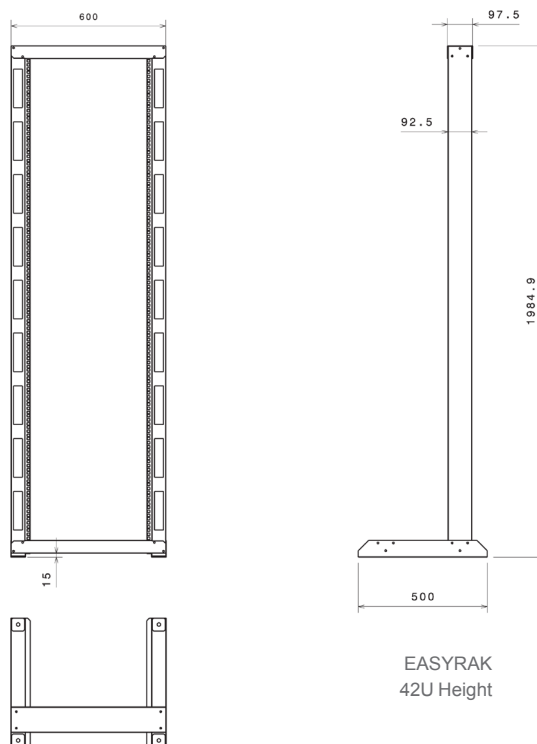

EASYRAK - RAL7035 double frame bayed execution

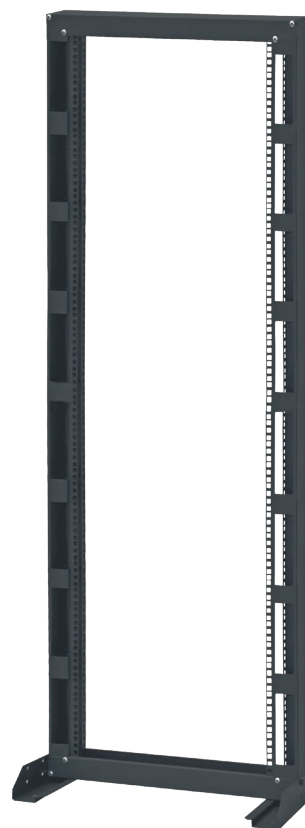

EASYRAK - RAL7016 execution

EASYRAK

Accessories

Mounting kit

Description	Order code
286 mm, frame included, Wall mounting bracket - RAL7035	VT052-251177
400 mm, frame included, Wall mounting bracket - RAL7035	VT052-257133
Floor standing kit (castors must be purchased separately) - RAL7035	VT052-255053

Baying kit

Description	Order code
Baying kit - RAL7035	VT052-244931

19" cantilever shelves

Description	Order code
255 mm cantilever shelf - RAL7035	VT802-562284

Fixed shelf 4 point fixing - Only for bayed frame

Description	Order code
2U fixed shelf kit 4 point fixing	VT052-255063

Top cover

Description	Order code
450 mm top cover - RAL7035	VT052-248074

Earth continuity kit

Description	Order code
Earth continuity kit	VT052-248075

Cantilever support


Description	Order code
2 Cantilever support - RAL7035	VT802-563106

Castors and feet kit


Description	Order code
Light / medium duty bracket / unbraked castors kit	VT802-560002
Adjustable feet	VT802-560001




Mounting kit

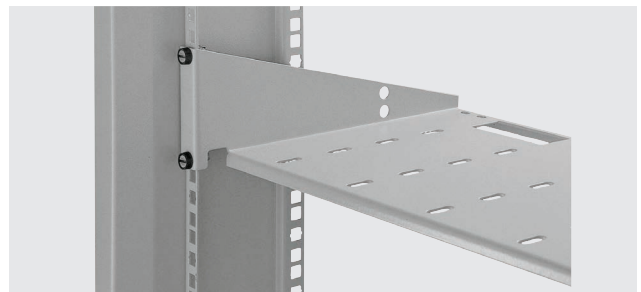

19" cantilever shelves

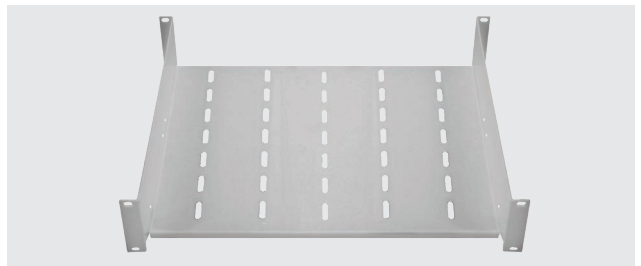

Fixed shelf 4 point fixing

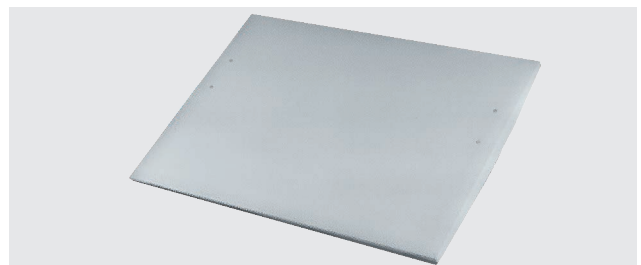

Top cover



Cantilever Support



Light / medium duty castors

GOMA ELETTRONICA SpA
10146 Torino - Italy
Strada Antica di Collegno, 225

Tel: +39 011 7725024

Fax: +39 011 712298

www.gomaelettronica.it

All trademarks are the property of their respective
owners GOMA ELETTRONICA SpA • P-CTG-EN1118