


rotary distributor

GF-3/8

Part number: 2095

FESTO

With one fixed air feed and four rotating outputs

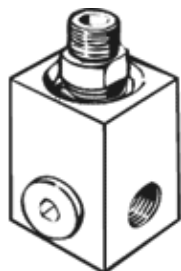

Data sheet

Feature	Value
Nominal size	15 mm
Assembly position	Any
Operating pressure complete temperature range	-0.95 ... 10 bar
Max. speed	300 1/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Pneumatic connection, port 1	Male thread G3/8
Pneumatic connection, port 2	Female thread G3/8
Materials note	Conforms to RoHS