



MAINS LED FLOODLIGHTS

Our LED flood light range make great replacements for halogen and metal halide flood lights and can be used for a fraction of the cost.

They are suitable for all weather conditions and can be used to light small and large areas.

With a 50,000 hour lifetime LED and very low power consumption these flood lights will dramatically reduce your electric bill.



10W


30W

50W

100W

200W

ECOSTAR & ECOSTAR WITH PIR

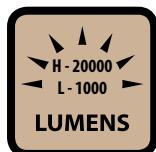

- 1000–20,000 Lumens
- High powered Epistar LED
- Robust aluminium casing
- Adjustable bracket
- Can operate on power sources between 110V - 240V
- Low heat emission = no cool down required before storage
- Compact design - smaller than fluorescent heads
- IP65 Rating



ECOSTAR

Manufactured in robust aluminium casing, these are IP65 rated (water and dust resistant) and covered by a 2 year warranty.

Fitted with a universal ballast, they can operate from a 110v-240v power source. Using LED means no replacement bulbs are required, and they offer a 500% increase in output per watt when compared to incandescent lights.

SPEC	10W	30W	50W	100W	200W
Light output (lumens)	1,000	3,000	5,000	10,000	20,000
Light source	10W LED	30W LED	50W LED	100W LED	200W LED
Beam angle	120°	120°	180°	180°	180°
Working voltage	100-240V	100-240V	100-240V	100-240V	100-240V
Product size (mm)	L206 x D150 x H49	L251x D169 x H66	L375 x D255 x H93	L376 x D255 x H93	L435 x D560 x H145
Product weight (kg)	1.100	2.250	4.750	4.750	8.200
Boxed size (mm)	L210 x D210 x H53	L260 x D250 x H75	L390 x D290 x H145	L390 x D290 x H145	L450 x D580 x H200
Boxed weight (kg)	1.16	2.400	5,000	5,000	8.500
Part no.	NSECOSTAR10 NSECOSTAR10PIR	NSECOSTAR30 NSECOSTAR30PIR NSECOSTAR30-110V LINKABLE	NSECOSTAR50 NSECOSTAR50PIR NSECOSTAR50-110V LINKABLE	NSECOSTAR100 NSECOSTAR100-110V- LINKABLE	NSECOSTAR200
CAT/PAD No.			0111/107623		

OPTIONAL EXTRAS

3.5m tripod | 1.7m tripod | 1m tripod | 13m extension lead | T Bar (required for 2 head option)

**HIGH POWER, LOW ENERGY LED FLOODLIGHT RANGE****110V LINKABLE OPTION**

The **ECOSTAR110V** linkable is the lighting solution for the industrial and construction market and outdoor events. Fitted with CEE 110V plug and socket allowing multiple lights to be linked together available in 30w, 50w and 100w. Linkable versions enable convenient 'daisychaining' and the LED energy efficiency allows very long cable runs. NightSearcher **ECOSTARS** are powered by LEDs so offer double the illumination for the same energy consumption and are the most efficient units available anywhere providing excellent performance and a notably shadow-free illumination.

The linkable is also available with double headed bracket and 1.7m or 3.5m extendable tripod.

