


Price* : 20.93 GBP

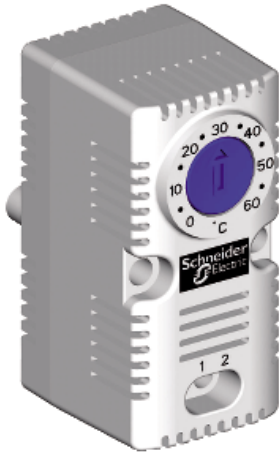

Main

Range	ClimaSys
Product name	ClimaSys CC
Product or component type	Simple thermostat
Temperature setting range	0...60 °C
Information displayed	Temperature in °C


Complementary

Input voltage	250 V
Sensor type	Bimetal
Contacts type and composition	NO
Contact resistance	< 10 mOhm
Service life in cycles	>= 100000 cycles
Maximum switching capacity	10 A 250 V AC resistive 15 A 120 V AC resistive 30 W DC 2 A 120...250 V AC inductive pf: 0.6
Electrical connection	4 terminals 2.5 mm ²
Mounting mode	Clipped
Height	External : 68 mm
Width	External : 33 mm
Depth	External : 44 mm
Product weight	40 g
Mounting location	On mounting plate 35 mm DIN rail Spacial upright Cross rails
Ambient air temperature for operation	-20...80 °C
IP degree of protection	IP20
Hysteresis	7 %
Number of outputs	1 output(s) ventilation function
Material	PC
Colour	Light grey

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Flame retardance	Self-extinguishing conforming to UL94 (material V0)
Product certifications	UL

Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 0940 - Schneider Electric declaration of conformity  Schneider Electric declaration of conformity
------------------------	---

Contractual warranty

Warranty period	18 months
-----------------	-----------
