

# C-SCFFI 2,5/4,8X0,5 - Connector

3240539

<https://www.phoenixcontact.com/gb/products/3240539>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Slip-on sleeve, fully isolated, blue, 1.5 ... 2.5 mm<sup>2</sup>, for plug 4.8 x 0.5 mm

## Your advantages

- Hard-soldered crimping zone for maximum conductor pull-out forces in connection with CRIMPFOX RCI... pliers
- Easy and reliable conductor entry thanks to 'EASY ENTRY'
- Halogen-free
- Electrogalvanized

## Commercial data

|                                      |                     |
|--------------------------------------|---------------------|
| Item number                          | 3240539             |
| Packing unit                         | 50 pc               |
| Minimum order quantity               | 50 pc               |
| Sales key                            | BH3451              |
| Product key                          | BH3451              |
| Catalog page                         | Page 500 (C-3-2019) |
| GTIN                                 | 4046356528092       |
| Weight per piece (including packing) | 1.125 g             |
| Weight per piece (excluding packing) | 1.125 g             |
| Customs tariff number                | 85369010            |
| Country of origin                    | CN                  |

# C-SCFFI 2,5/4,8X0,5 - Connector

3240539

<https://www.phoenixcontact.com/gb/products/3240539>




## Technical data

### Product properties

|                  |                          |
|------------------|--------------------------|
| Product type     | Connector                |
| Product property | Halogen-free             |
|                  | With “Easy Entry” system |
|                  | Brazed                   |
|                  | PA-insulated             |

### Dimensions
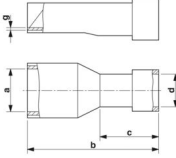
|                                           |                                                                                    |
|-------------------------------------------|------------------------------------------------------------------------------------|
| Dimensional drawing                       |  |
| Width                                     | 4.8 mm                                                                             |
| Sleeve length                             | 20 mm                                                                              |
| Length of the insulating material sleeve  | 11 mm                                                                              |
| Maximum stripping length                  | 8 mm                                                                               |
| Min. material thickness                   | 0.4 mm                                                                             |
| Inner dimensions of the insulating collar | 5 mm                                                                               |

### Material specifications

|                                        |                   |
|----------------------------------------|-------------------|
| Color                                  | blue (RAL 5015)   |
| Material                               | Brass             |
| Flammability rating according to UL 94 | V2                |
| Coating                                | electrogalvanized |
| Insulating material                    | PA                |
| Components                             | halogen-free      |

### Mechanical properties

|                |       |
|----------------|-------|
| Technical data |       |
| Sleeve length  | 20 mm |

### Environmental and real-life conditions

|                                 |                   |
|---------------------------------|-------------------|
| Ambient conditions              |                   |
| Ambient temperature (operation) | -20 °C ... 105 °C |
| Permanent temperature           | 105 °C            |
| Short-term temperature          | 120 °C            |

# C-SCFFI 2,5/4,8X0,5 - Connector


3240539

<https://www.phoenixcontact.com/gb/products/3240539>



## Drawings

Dimensional drawing

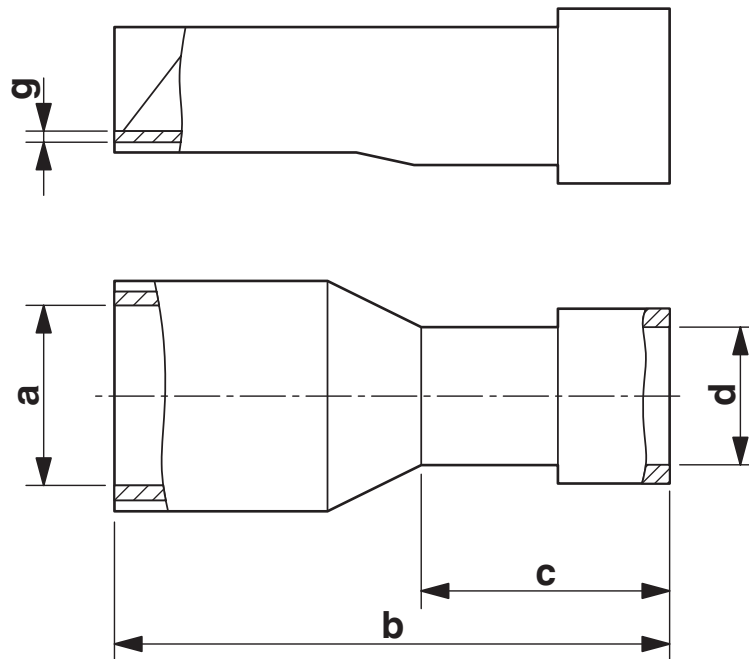

# C-SCFFI 2,5/4,8X0,5 - Connector

3240539

<https://www.phoenixcontact.com/gb/products/3240539>



## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27400204 |
|-------------|----------|

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC001052 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 27121700 |
|-------------|----------|

# C-SCFFI 2,5/4,8X0,5 - Connector

3240539

<https://www.phoenixcontact.com/gb/products/3240539>



## Environmental product compliance

### EU RoHS

|                                         |                    |
|-----------------------------------------|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|-----------------------------------------|--------------------|

### China RoHS

|                                        |                                          |
|----------------------------------------|------------------------------------------|
| Environment friendly use period (EFUP) | EFUP-E                                   |
|                                        | No hazardous substances above the limits |

### EU REACH SVHC

|                                     |                            |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

PHOENIX CONTACT Ltd  
Halesfield 13, Telford  
Shropshire, TF7 4PG  
01952 681700  
[info@phoenixcontact.co.uk](mailto:info@phoenixcontact.co.uk)