




## LED FIL C35 Tip GS4 E14 DIM 4W (35W) 400lm 827 Clear

Article number: 147023

BAI LED Filament Dimmable Candle Tip C35 E14 4W 2700K Clear 400lm (35W) 230V-240V 320° 35x120mm BA35 LED-lamp

This LED filament bulb is the energy-saving evolution of the traditional incandescent lamp. The advanced filaments replace the old-fashioned wire, offering a warm glow while consuming significantly less power and lasting much longer. With its clear glass and elegant tip, this candle bulb is perfect for classic chandeliers, wall sconces, and decorative fixtures. A timeless look with a sustainable twist.

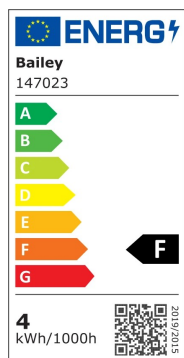

### General ETIM properties

|               |                                                         |
|---------------|---------------------------------------------------------|
| ETIM group    | Lamps                                                   |
| ETIM class    | LED-lamp/Multi-LED                                      |
| Name          | LED FIL C35 Tip GS4 E14 DIM 4W (35W)<br>400lm 827 Clear |
| Brand         | Bailey                                                  |
| Productseries | LED Filament candle                                     |
| Producttype   | C35 TIP E14 827 CL                                      |

## ETIM specifications

|                                                 |                     |
|-------------------------------------------------|---------------------|
| Socket                                          | E14                 |
| Luminous flux [lm]                              | 400 - 400           |
| Nominal voltage [V]                             | 220 - 240           |
| Lamp power [W]                                  | 4 - 4               |
| Colour temperature [K]                          | 2700 - 2700         |
| Diameter [mm]                                   | 35                  |
| Length [mm]                                     | 120                 |
| Dimmable                                        | Yes                 |
| Lamp shape                                      | Candle              |
| Beam angle [°]                                  | 320 - 320           |
| Colour                                          | White               |
| Type of glass/cover                             | Clear               |
| Lamp designation                                | Other               |
| Colour rendering index CRI                      | 80-89               |
| Voltage type                                    | AC                  |
| Filament lamp                                   | Yes                 |
| Rated luminous flux according to IEC 62612 [lm] | 400                 |
| Power factor                                    | 0.9                 |
| Lamp efficacy [lm/W]                            | 100                 |
| Nominal current [mA]                            | 20 - 20             |
| Colour of light according to EN 12464-1         | Warm white < 3300 K |
| Housing colour                                  | Colourless          |
| Average nominal lifetime [h]                    | 15000               |
| Degree of protection (IP)                       | IP20                |
| Colour consistency (McAdam ellipse)             | SDCM6               |
| Min. number of switching cycles                 | 15000               |
| Weighted energy consumption in 1000 hours [kWh] | 4                   |
| Remote operation possible                       | No                  |
| With movement sensor                            | No                  |
| With remote control                             | No                  |
| Photobiological safety according to EN 62471    | RG0                 |
| Compatible with Apple HomeKit                   | No                  |
| Compatible with Google Assistant                | No                  |
| Compatible with Amazon Alexa                    | No                  |
| IFTTT support available                         | No                  |
| Suitable for electronic ballast                 | No                  |
| Suitable for magnetic ballast                   | No                  |
| Dimming phase cut-off (trailing edge)           | Yes                 |
| Dimming phase cut-on (leading edge)             | Yes                 |
| Dimming Touch and Dim                           | No                  |
| Dimming Zigbee                                  | No                  |

|                                                              |       |
|--------------------------------------------------------------|-------|
| Dimming Bluetooth                                            | No    |
| Dimming Wi-Fi                                                | No    |
| Energy efficiency class according to EU regulation 2019/2015 | F     |
| With twilight switch                                         | No    |
| Material of light bulb                                       | Glass |